




Splitter T

Y-splitter/STM12/2xUS

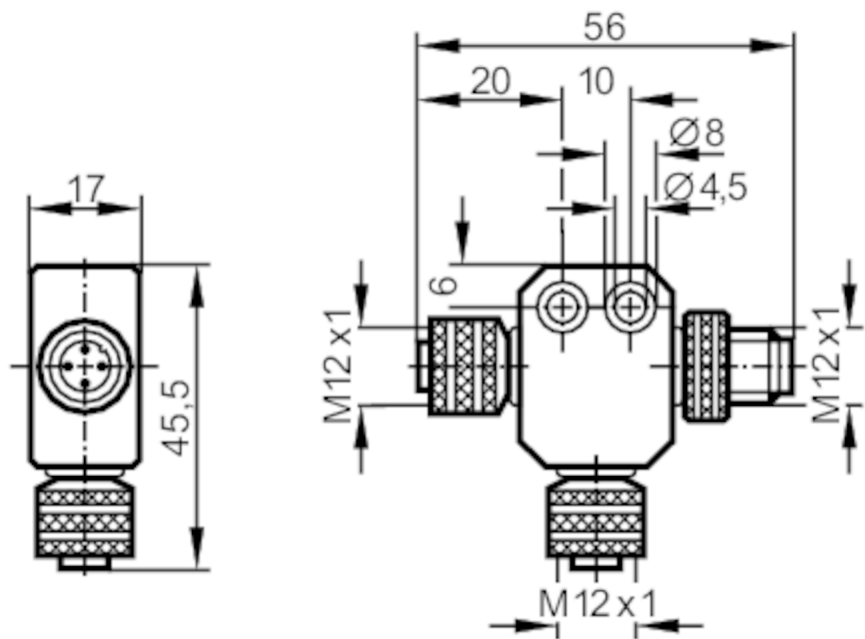

Aplikasi		
Desain		untuk sensor tekanan PNI
Data kelistrikan		
Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
Beban arus maks. per modul/slot	[A]	3
Total beban arus maks.	[A]	3
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68
Data teknis		
Berat	[g]	38
Material		PUR
Keterangan		
Keterangan		orientasi konektor A/B vertikal (untuk sensor vertikal)
Jumlah paket		1 buah

Splitter T

Y-splitter/STM12/2xUS

Koneksi listrik

Koneksi

