


E11697



Kabel koneksi dengan soket

ADOAO140MSS0005B11

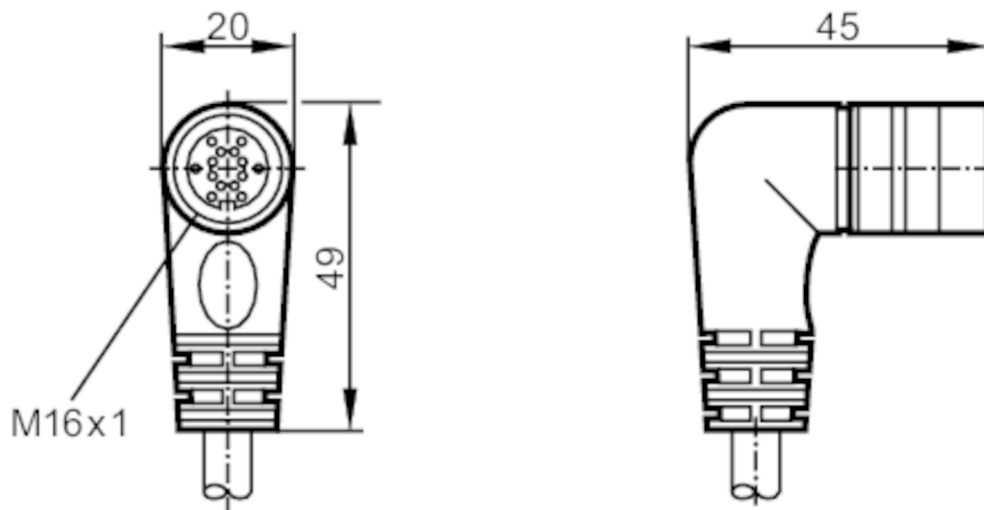

Data kelistrikan

Tegangan pengoperasian	[V]	< 30 DC
Total beban arus maks.	[A]	3

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Berat	[g]	421.5
Dimensi	[mm]	45 x 20 x 49
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E11697



Kabel koneksi dengan soket


ADOAO140MSS0005B11

Koneksi listrik

Kabel: 5 m, PUR, hitam, Ø 7.5 mm; 2 x 0.34 mm² (14 x Ø 0.15 mm) + 10 x 0.25 mm² (7 x Ø 0.2 mm)

Koneksi listrik - soket

Konektor: 1 x M16, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

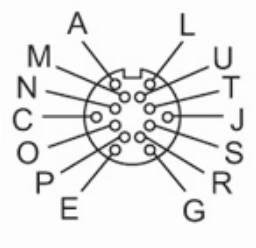

Koneksi

A	BN
C	GY/PK
E	BK
G	PK
J	GN
L	BU
N	RD/BU
O	VT
P	WH
R	RD
S	GY
T	YE

M:	tidak digunakan
U:	tidak digunakan
	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
VT =	ungu
WH =	putih
YE =	kuning
RD =	merah