

ZDO4H050MSS0000-00STAK190MSS

Produk alternatif: EBC003

[illegible]

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon	ya

Tegangan pengoperasian	[V]	< 60 AC / < 75 DC
Kelas perlindungan		II
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	10

Suhu sekitar	[°C]	-15...80
Perlindungan		IP 67

Kotak splitter


ZDO4H050MSS0000-00STAK190MSS

Data teknis		
Dimensi	[mm]	28 x 60 x 118
Material		TPU
Material bodi detakan		TPU
Jumlah port kotak splitter		4
Tipe konektor		M12


Keterangan		
Jumlah paket		1 buah

Koneksi listrik - Koneksi

Konektor: 1 x M23; Bodi cetakan: TPU; Kontak: dilapisi emas; Torsi pengencangan: 0.5 Nm

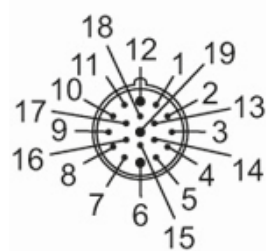

Koneksi

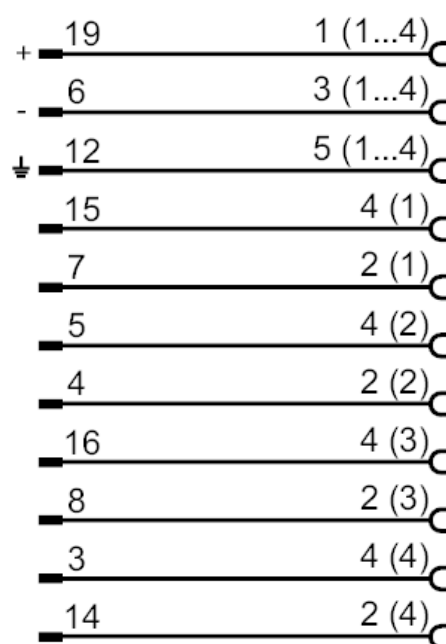

E11728



Kotak splitter

ZDO4H050MSS0000-00STAK190MSS

Koneksi listrik - slot

Konektor: 4 x M12; pengkodean: A; Bodi cetakan: TPU; Kontak: dilapisi emas; Torsi pengencangan: 0.5 Nm

