

ZDO6H050MSS0005H11

Produk alternatif: EBC018

Technical drawing of the 125mm x 60mm x 18mm connector. The drawing includes three views: top, side, and front. The top view shows a rectangular plate with six circular ports arranged in two rows of three. The ports are numbered 1 through 6. The top view dimensions are 125mm by 60mm. The side view shows the profile of the connector with a height of 18mm. The front view shows the connector with a width of 107mm and a height of 36mm. The connector is labeled M12x1.

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas
Bebas dari silikon	ya

Tegangan pengoperasian	[V]	< 60 AC / < 75 DC
Kelas perlindungan		II
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	12

Suhu sekitar	[°C]	-15...80
Perlindungan		IP 67



Kotak splitter

ZDO6H050MSS0005H11

Data teknis

Material	TPU
Material bodi detakan	TPU
Jumlah port kotak splitter	6
Tipe konektor	M12

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 10.4 mm; 12 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Koneksi listrik - slot

Konektor: 6 x M12; pengkodean: A; Bodi cetakan: TPU; Kontak: dilapisi emas; Torsi pengencangan: 0.5 Nm

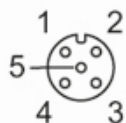



Kotak splitter

ZDO6H050MSS0005H11

Koneksi

<u>BN</u>	1 (1...6)	C
<u>BU</u>	3 (1...6)	C
<u>GN/YE</u>	5 (1...6)	C
<u>GY/PK</u>	2 (1)	C
<u>RD/BU</u>	2 (2)	C
<u>WH/GN</u>	2 (3)	C
<u>BN/GN</u>	2 (4)	C
<u>WH/YE</u>	2 (5)	C
<u>YE/BN</u>	2 (6)	C
<u>WH</u>	4 (1)	C
<u>GN</u>	4 (2)	C
<u>YE</u>	4 (3)	C
<u>GY</u>	4 (4)	C
<u>PK</u>	4 (5)	C
<u>RD</u>	4 (6)	C

BN =	Warna core :
BU =	coklat
GN =	biru
GY =	hijau
PK =	abu-abu
RD =	merah muda
WH =	merah
YE =	putih
	kuning