

E11737



Kabel koneksi dengan soket

ADOGK120MSS0010H12



Aplikasi

Fitur khusus

Bebas halogen

Data kelistrikan

Tegangan pengoperasian

[V]

< 63 AC/DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-25...80

Perlindungan

IP 67

Data teknis

Berat

[g]

1388.5

Dimensi

[mm]

26 x 26 x 85

Material

PUR hitam

Material bodi detakan

PUR

Material mur

kuningan, berlapis nikel

Torsi pengencangan

[Nm]

2

Keterangan

Jumlah paket

1 buah



Kabel koneksi dengan soket


ADOGK120MSS0010H12

Koneksi listrik

Kabel: 10 m, PUR, Bebas halogen, hitam, Ø 9.3 mm; 8 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M23, lurus; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

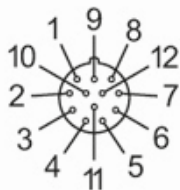

Koneksi

1	WH
2	GN
3	YE
4	GY
5	GY/PK
6	RD/BU
7	WH/GN
8	BN/GN
9	BU
10	
11	BN
12	YE/GN

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
WH =	putih
YE =	kuning