


E11739



Kabel koneksi dengan soket

ADOAK120MSS0005H12

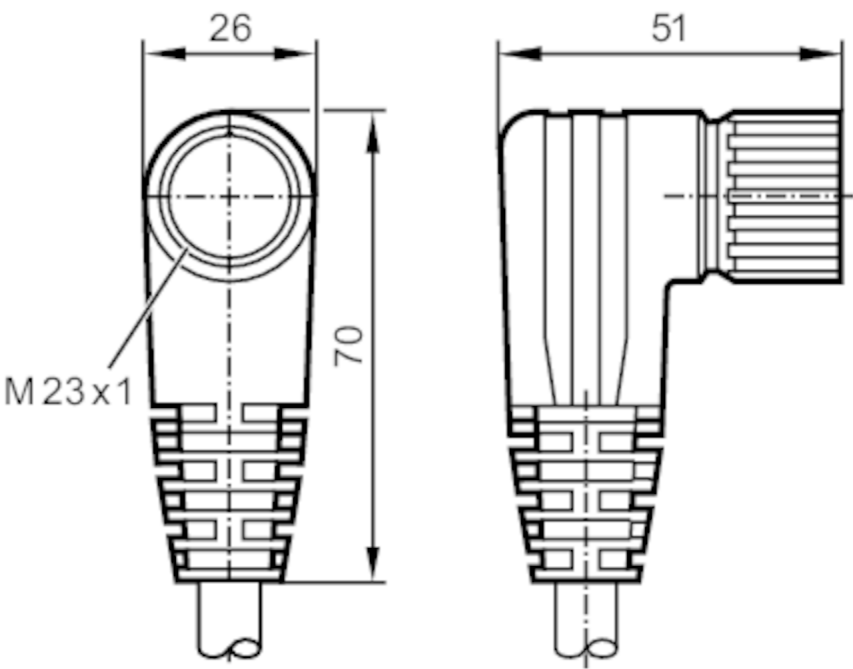

Aplikasi		
Fitur khusus		Bebas halogen
Data kelistrikan		
Tegangan pengoperasian	[V]	< 63 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67
Data teknis		
Berat	[g]	748.5
Dimensi	[mm]	51 x 26 x 70
Material		PUR hitam
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Torsi pengencangan	[Nm]	2
Keterangan		
Jumlah paket		1 buah



Kabel koneksi dengan soket


ADOAK120MSS0005H12

Koneksi listrik

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 9.3 mm; 8 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M23, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

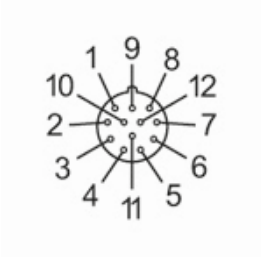

Koneksi

1	WH
2	GN
3	YE
4	GY
5	GY/PK
6	RD/BU
7	WH/GN
8	BN/GN
9	BU
10	
11	BN
12	YE/GN

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
WH =	putih
YE =	kuning