


E11741



Kabel koneksi dengan soket

ADOAK120MSS0015H12

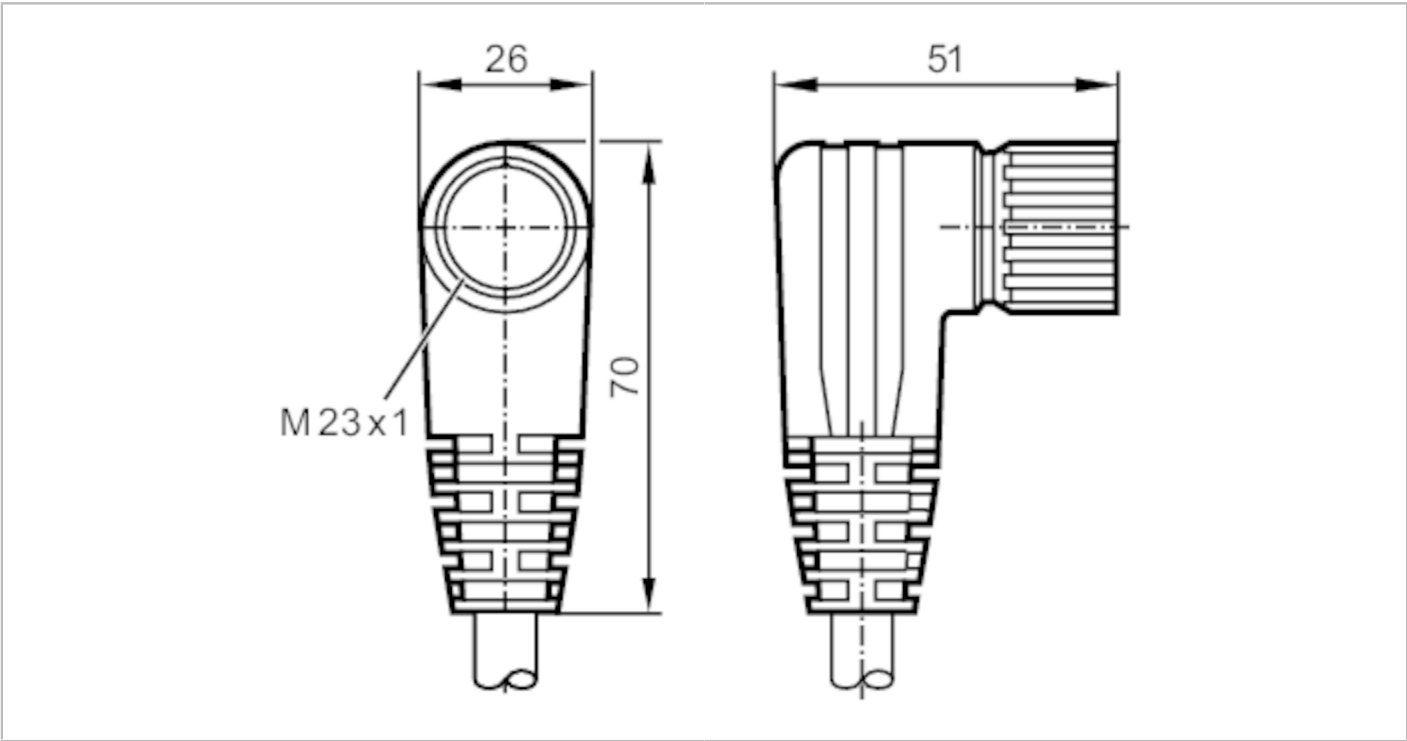

Aplikasi		
Fitur khusus		Bebas halogen
Data kelistrikan		
Tegangan pengoperasian	[V]	< 63 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67
Data teknis		
Berat	[g]	2055
Dimensi	[mm]	51 x 26 x 70
Material		PUR hitam
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Torsi pengencangan	[Nm]	2
Keterangan		
Jumlah paket		1 buah

Kabel koneksi dengan soket

ADOAK120MSS0015H12

Koneksi listrik

Kabel: 15 m, PUR, Bebas halogen, hitam, Ø 9.3 mm; 8 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M23, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel



Koneksi



Warna core :

BN = coklat

BU = biru

GN = hijau

GY = abu-abu

PK = merah muda

RD = merah

WH = putih

YE = kuning