


E11742



Kabel koneksi dengan soket

ADOGK190MSS0005H19

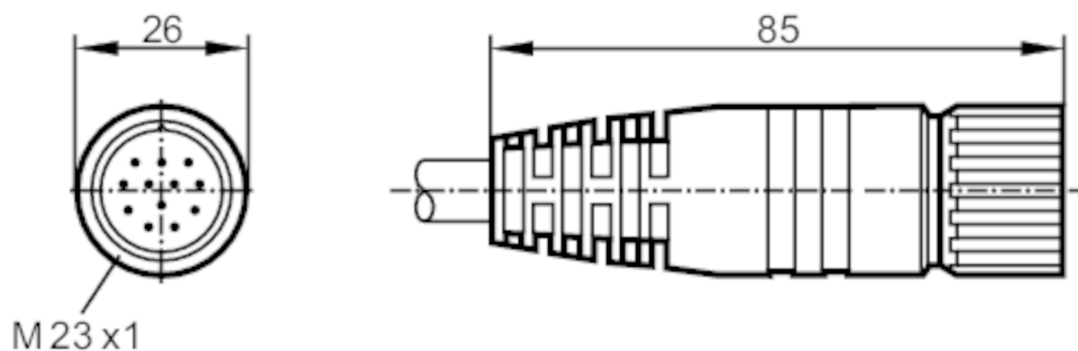

Aplikasi

Fitur khusus	Bebas halogen
--------------	---------------

Data kelistrikan

Tegangan pengoperasian	[V]	< 63 AC/DC
Total beban arus maks.	[A]	8

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67

Data teknis

Berat	[g]	1141
Dimensi	[mm]	26 x 26 x 85
Material		PUR hitam
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Torsi pengencangan	[Nm]	2

Keterangan

Jumlah paket	1 buah
--------------	--------

E11742



Kabel koneksi dengan soket


ADOGK190MSS0005H19

Koneksi listrik

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 11.6 mm; 16 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M23, lurus; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

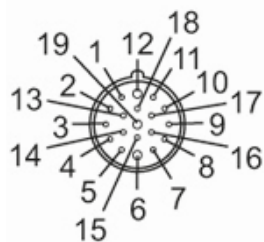



Kabel koneksi dengan soket

ADOGK190MSS0005H19

Koneksi

1	VT
2	RD
3	GY
4	RD/BU
5	GN
6	BU
7	GY/PK
8	WH/GN
9	WH/YE
10	WH/GY
11	BK
12	GN/YE
13	YE/BN
14	BN/GN
15	WH
16	YE
17	PK
18	GY/BN
19	BN

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning