

E11744



Kabel koneksi dengan soket

ADOGK190MSS0015H19



Aplikasi

Fitur khusus

Bebas halogen

Data kelistrikan

Tegangan pengoperasian

[V]

< 63 AC/DC

Total beban arus maks.

[A]

8

Kondisi pengoperasian

Suhu sekitar

[°C]

-25...80

Perlindungan

IP 67

Data teknis

Berat

[g]

3140.5

Dimensi

[mm]

26 x 26 x 85

Material

PUR hitam

Material bodi detakan

PUR

Material mur

kuningan, berlapis nikel

Torsi pengencangan

[Nm]

2

Keterangan

Jumlah paket

1 buah

E11744



Kabel koneksi dengan soket


ADOGK190MSS0015H19

Koneksi listrik

Kabel: 15 m, PUR, Bebas halogen, hitam, $\varnothing$ 11.6 mm; 16 x 0.5 mm² (63 x $\varnothing$ 0.1 mm) + 3 x 1.0 mm² (127 x $\varnothing$ 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M23, lurus; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

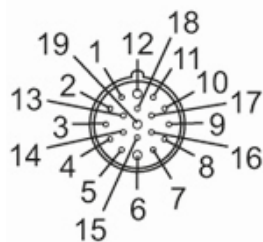



Kabel koneksi dengan soket

ADOGK190MSS0015H19

Koneksi

1	VT
2	RD
3	GY
4	RD/BU
5	GN
6	BU
7	GY/PK
8	WH/GN
9	WH/YE
10	WH/GY
11	BK
12	GN/YE
13	YE/BN
14	BN/GN
15	WH
16	YE
17	PK
18	GY/BN
19	BN

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning