


E11746



Kabel koneksi dengan soket

ADOAK190MSS0010H19

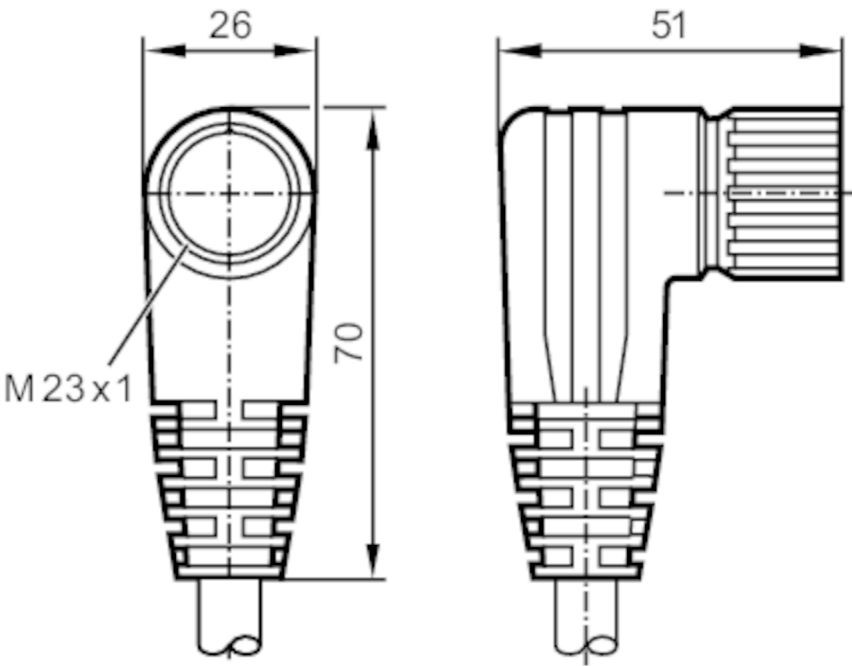

Aplikasi		
Fitur khusus		Bebas halogen; Kesesuaian rantai tarik
Data kelistrikan		
Tegangan pengoperasian	[V]	< 63 AC/DC
Total beban arus maks.	[A]	8
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67
Data teknis		
Berat	[g]	2239
Dimensi	[mm]	51 x 26 x 70
Material		PUR hitam
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Torsi pengencangan	[Nm]	2
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	kecepatan pergerakan	maks. 2 m/s
	siklus pembengkokan	> 500000
	ketegangan torsional	± 30 °/m
Keterangan		
Jumlah paket		1 buah

E11746



Kabel koneksi dengan soket


ADOAK190MSS0010H19

Koneksi listrik

Kabel: 10 m, PUR, Bebas halogen, hitam, $\varnothing$ 11.6 mm; 16 x 0.5 mm² (63 x $\varnothing$ 0.1 mm) + 3 x 1.0 mm² (127 x $\varnothing$ 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M23, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

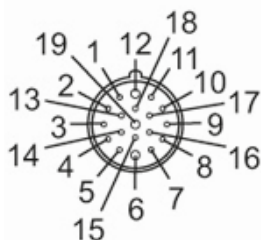



Kabel koneksi dengan soket

ADOAK190MSS0010H19

Koneksi

1	VT
2	RD
3	GY
4	RD/BU
5	GN
6	BU
7	GY/PK
8	WH/GN
9	WH/YE
10	WH/GY
11	BK
12	GN/YE
13	YE/BN
14	BN/GN
15	WH
16	YE
17	PK
18	GY/BN
19	BN

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning