


Soket adaptor

EDOGH050MSS00,7E05(M16)

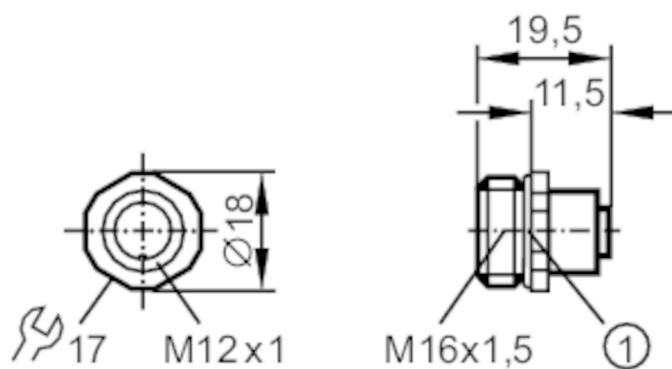

1 O-ring



Data kelistrikan

Tegangan pengoperasian	[V]	< 125 AC/DC
------------------------	-----	-------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68

Data teknis

Berat	[g]	25.1
Ulir pemasangan		M16
Material		seng tuang berlapis nikel
Material bodi detakan		seng tuang, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E11917



Soket adaptor


EDOGH050MSS00,7E05(M16)

Koneksi listrik


Kabel: 0.7 m, PVC; 4 x 0.25 mm² + 1 x 0.5 mm²

Koneksi listrik - soket

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: seng tuang, berlapis nikel

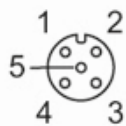

Koneksi

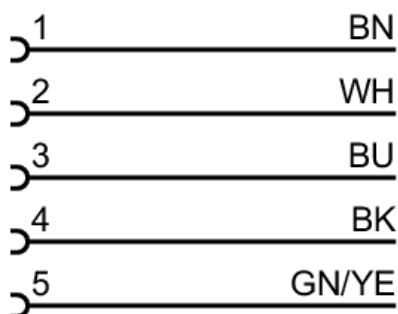

BK =	Warna core :
BN =	hitam
BU =	coklat
GN/YE =	biru
WH =	hijau/kuning
	putih