


Kabel jumper dengan soket katup

AVDAA031PLS0010H03

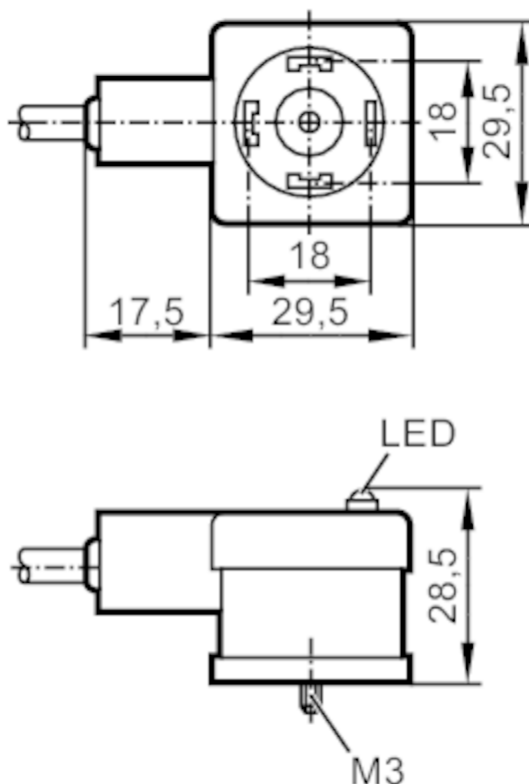

Aplikasi		
Fitur khusus	Bebas dari silikon; Bebas halogen	
Bebas dari silikon		
ya		
Data kelistrikan		
Tegangan pengoperasian	[V]	< 24 AC/DC
Pelindung tegangan berlebih		ya; (VDR)
Total beban arus maks.	[A]	5
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...80
Perlindungan		IP 67
Data teknis		
Berat	[g]	491.5
Dimensi	[mm]	28.5 x 29.5 x 47
Material		PP; FKM
Material bodi detakan		PP / FPM
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Keterangan		
Jumlah paket	1 buah	

E11991



Kabel jumper dengan soket katup


AVDAA031PLS0010H03

Koneksi listrik


Kabel: 10 m, PUR, Bebas halogen, Ø 6.6 mm; 3 x 0.5 mm² / AWG 20

Koneksi listrik - soket

Konektor: 1 x katup tipe A DIN, bersiku; Bodi cetakan: PP / FPM

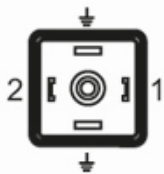

Koneksi

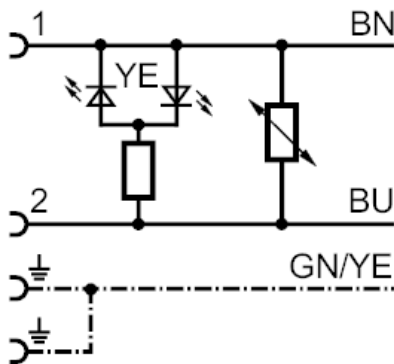

BN =
BU =
GN/YE =

Warna core :
coklat
biru
hijau/kuning