




Kabel koneksi

VDOGF030MSS0001I03STGH030MSS

Produk tidak tersedia - entri arsip

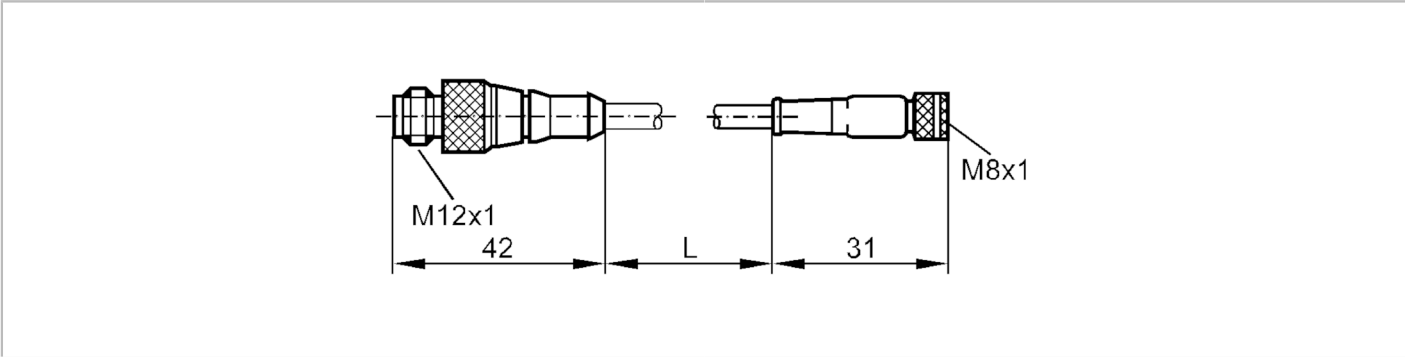

Aplikasi

Fitur khusus	Bebas halogen
--------------	---------------

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
Kelas perlindungan		III

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis


Material	TPU
Material bodi detakan	TPU
Material mur	kuningan, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

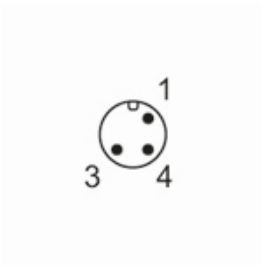




Kabel koneksi

VDOGF030MSS0001I03STGH030MSS

Koneksi listrik

Kabel: 1 m, PUR, Bebas halogen; terkoneksi silang; 3 x 0.34 mm²

Koneksi

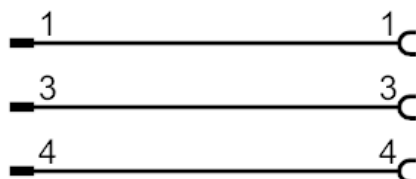

Koneksi listrik - soket

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

