


Kabel koneksi

VSTGH030MSS0005I03DOAF030MSS

Produk tidak tersedia - entri arsip

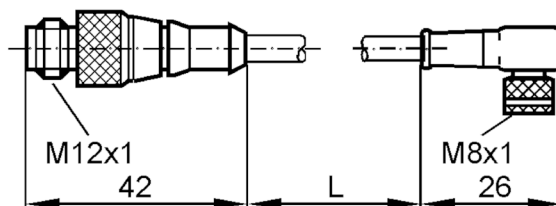

Aplikasi

Fitur khusus

Bebas halogen

Data kelistrikan

Tegangan pengoperasian [V]

10...30 DC

Kelas perlindungan

III

Kondisi pengoperasian

Suhu sekitar [°C]

-25...90

Perlindungan

IP 67

Data teknis

Material

TPU

Material bodi detakan

TPU

Material mur

kuningan, berlapis nikel

Keterangan

Jumlah paket

1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel






Kabel koneksi

VSTGH030MSS0005I03DOAF030MSS

Koneksi listrik

Kabel: 5 m, PUR, Bebas halogen; terkoneksi silang; 3 x 0.34 mm²

Koneksi

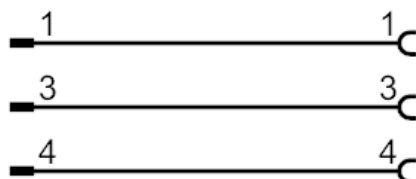

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

