


E11016



Kabel koneksi dengan soket

ADOAK120MSS0014B12

Produk tidak tersedia - entri arsip

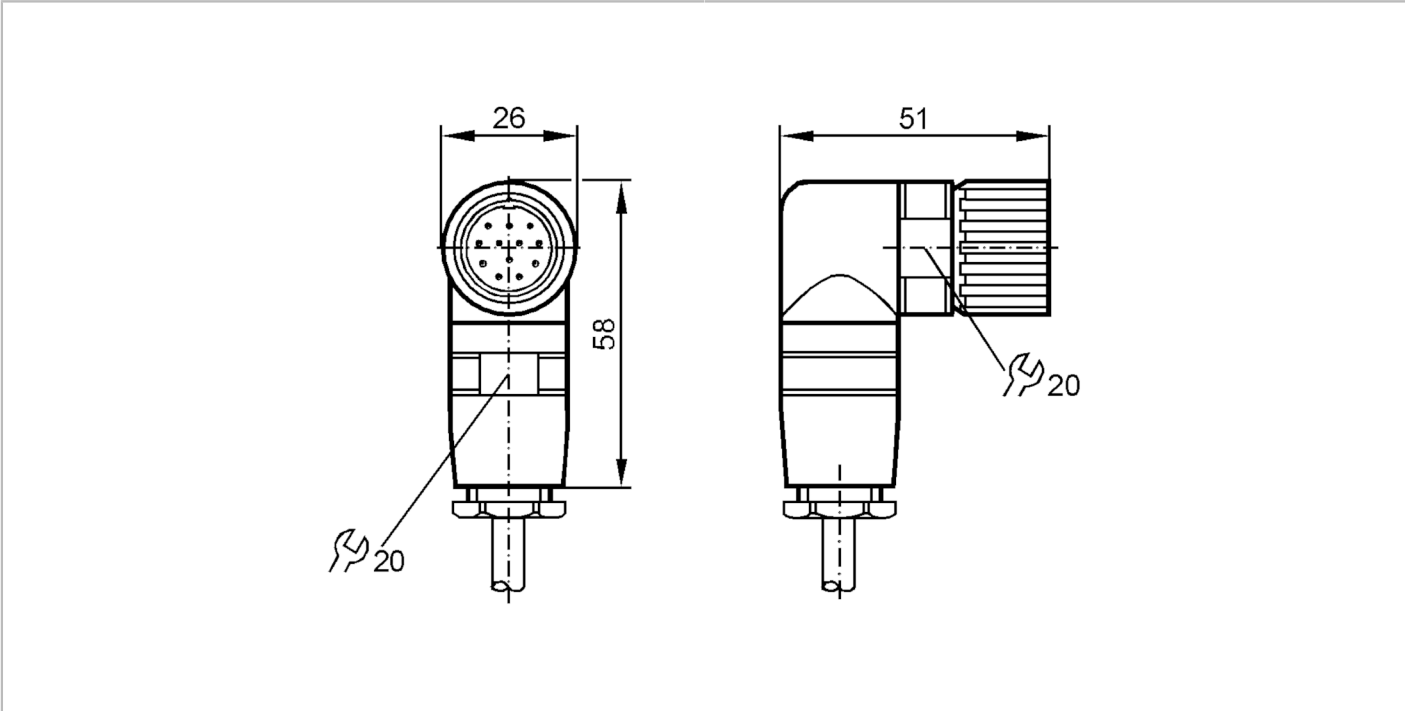

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 65

Data teknis

Dimensi	[mm]	51 x 26 x 58
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel
Material mur		kuningan, berlapis nikel

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 14 m, PUR, hitam, Ø 11 mm; 12 x 1.0 mm²

Koneksi listrik - colokan

Konektor: 1 x M23, bersiku; Bodi cetakan: kuningan, berlapis nikel; Penguncian: kuningan, berlapis nikel

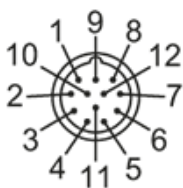

E11016



Kabel koneksi dengan soket

ADOAK120MSS0014B12

Koneksi