

Technical drawing of the 125mm long connector, showing top and front views with dimensions.

Top View Dimensions:

- Overall length: 125
- Pin diameter: 11
- Pin height: 18

Front View Dimensions:

- Overall width: 60
- Pin diameter: 11
- Pin height: 39
- Mounting hole diameter: 4,5
- Overall length: 107
- Mounting hole pitch: M12x1

The front view shows six circular pin sockets arranged in two rows of three. The top row is numbered 1, 2, and 3 from left to right, and the bottom row is numbered 4, 5, and 6 from left to right. A dashed line indicates the center of the connector.

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas
Bebas dari silikon	ya

Tegangan pengoperasian	[M]	10...30 DC
Kelas perlindungan		II
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	12

Desain kelistrikan	PNP
--------------------	-----

Suhu sekitar	[°C]	-15...80
Perlindungan		IP 67



Kotak splitter

ZDO6H05DMSS0010H15

Data teknis

Material	TPU
Material bodi detakan	TPU
Jumlah port kotak splitter	6
Tipe konektor	M12

Elemen display/pengoperasian

Display	status peralihan	12 x LED, kuning
	operasi	1 x LED, hijau

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 10 m, PUR, Bebas halogen; 12 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Koneksi listrik - slot


Konektor: 6 x M12; pengkodean: A; Bodi cetakan: TPU; Kontak: dilapisi emas; Torsi pengencangan: 0.5 Nm

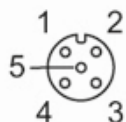

Kotak splitter

ZDO6H05DMSS0010H15

Koneksi

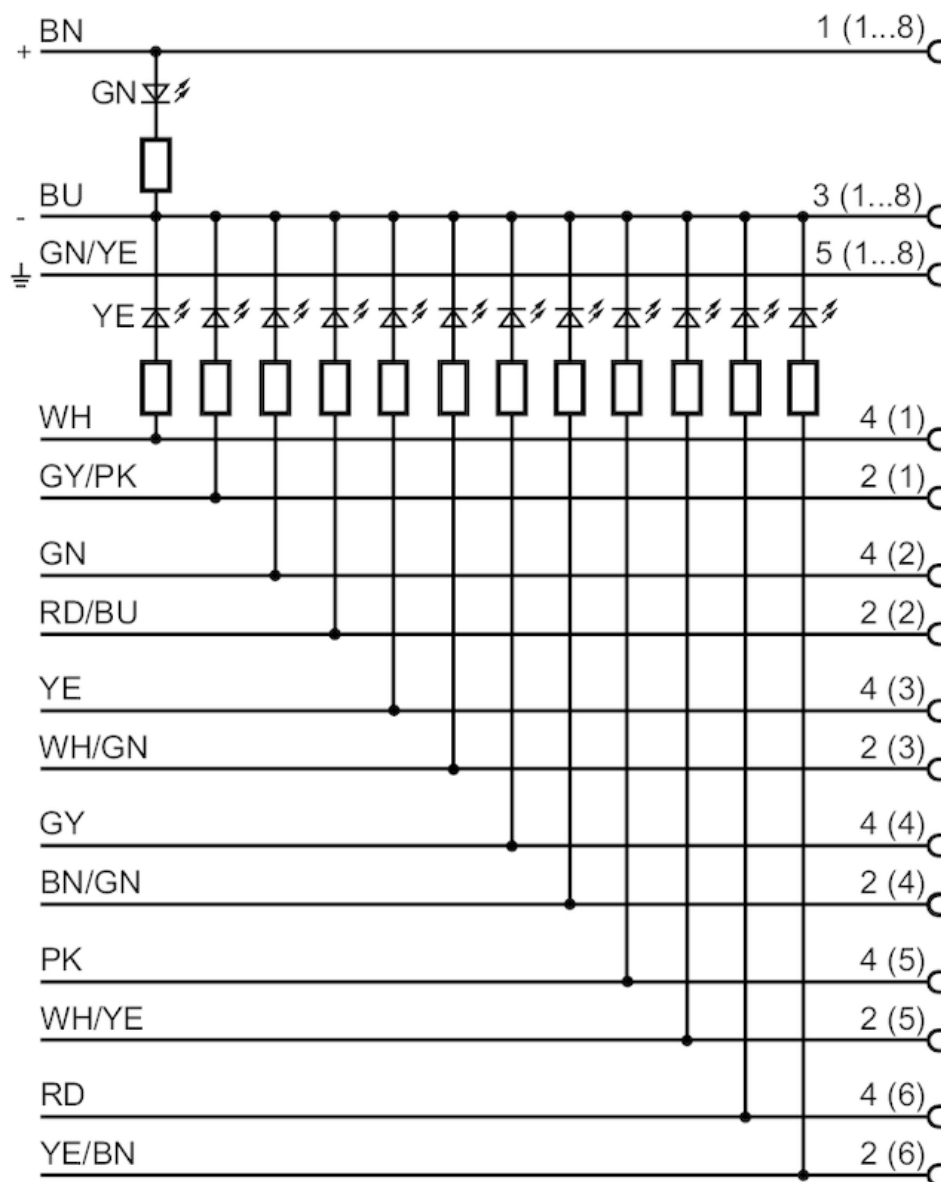

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
WH =	putih
YE =	kuning