


Adaptor pemasangan untuk sensor kapasitif

MOUNTING ADAPTER D34MM POM

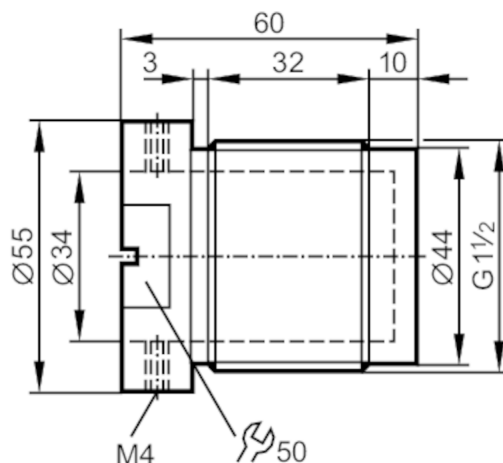

Aplikasi		
Peringkat tekanan	[bar]	8
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Data teknis		
Berat	[g]	83.7
Dimensi	[mm]	G 1 1/2 / L = 60
Penamaan ulir		G 1 1/2
Material		Adaptor: POM
Koneksi sensor		adaptor klem Ø 34 mm
Koneksi proses		koneksi berulir G 1 1/2 ulir eksternal
Keterangan		
Jumlah paket		1 buah