


Adaptor pemasangan untuk sensor kapasitif

MOUNTING ADAPTER M30 POM

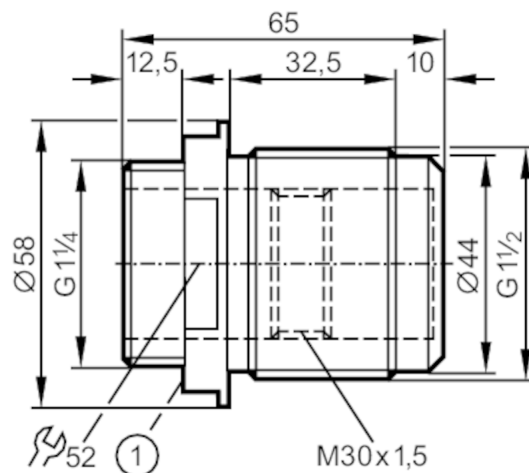

1 O-ring 44 x 2 mm



Aplikasi

Suhu media	[°C]	-25...100
Suhu media pada waktu singkat	[°C]	-25...110
Peringkat tekanan	[bar]	8

Data teknis

Berat	[g]	90.5
Dimensi	[mm]	G 1 1/2 / L = 65
Penamaan ulir		G 1 1/2
Material		Adaptor: POM; Gasket: EPDM
Koneksi sensor		koneksi berulir M30 x 1,5 ulir internal
Koneksi proses		koneksi berulir G 1 1/2 ulir eksternal

Keterangan

Jumlah paket	1 buah
--------------	--------