


E11034



Adaptor pemasangan untuk sensor kapasitif

MOUNTING ADAPTER M30 PVDF

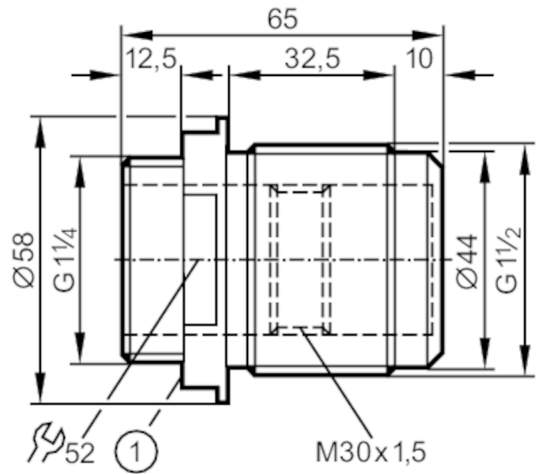

1 O-ring 44 x 2 mm

Aplikasi		
Peringkat tekanan	[bar]	8
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...110
Data teknis		
Berat	[g]	114.6
Dimensi	[mm]	G 1 1/2 / L = 65
Penamaan ulir		G 1 1/2
Material		Adaptor: PVDF; Gasket: EPDM
Koneksi sensor		koneksi berulir M30 x 1,5 ulir internal
Koneksi proses		koneksi berulir G 1 1/2 ulir eksternal
Keterangan		
Jumlah paket		1 buah