


Kabel koneksi

VDOAH042MSS0003A03STGH030MSS

Produk tidak tersedia - entri arsip

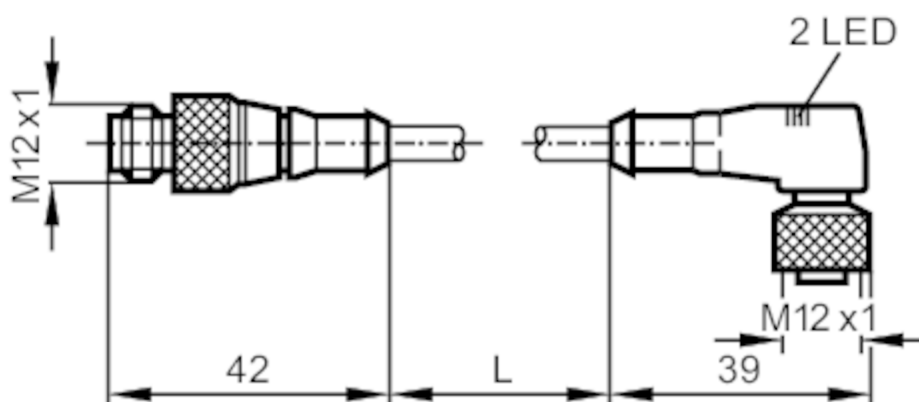

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
--------------	------	----------

Perlindungan	IP 67
--------------	-------

Data teknis

Material	PUR
----------	-----

Material bodi detakan	PUR
-----------------------	-----

Material mur	kuningan, berlapis nikel
--------------	--------------------------

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------



Kabel koneksi

VDOAH042MSS0003A03STGH030MSS

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



Koneksi listrik

Kabel: 3 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (180 x Ø 0.05 mm)

Koneksi

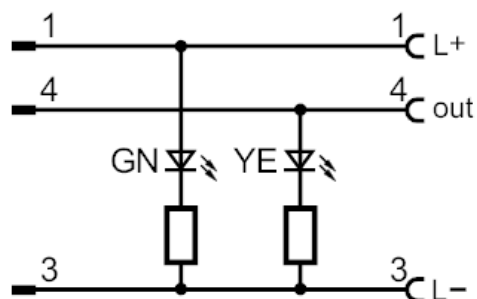

Warna core :
 BK = hitam
 BN = coklat
 BU = biru

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

