


Kabel koneksi dengan soket

ADOAF030MSS0002A03

Produk tidak tersedia - entri arsip

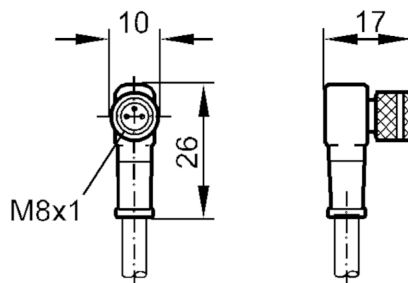

Data kelistrikan

Tegangan pengoperasian [V]	< 60 AC / < 75 DC
Kelas perlindungan	III

Kondisi pengoperasian

Suhu sekitar [°C]	-25...90
Perlindungan	IP 67

Data teknis

Dimensi [mm]	17 x 10 x 26
Material	TPU
Material bodi detakan	TPU
Material mur	kuningan, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 2 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm²

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



E11060



Kabel koneksi dengan soket

ADOAF030MSS0002A03

Koneksi



BN =	Warna core :	coklat
BK =		hitam
BU =		biru