


E11067



Soket adaptor

EDOGH040ZDS00,5E04 (PG9)

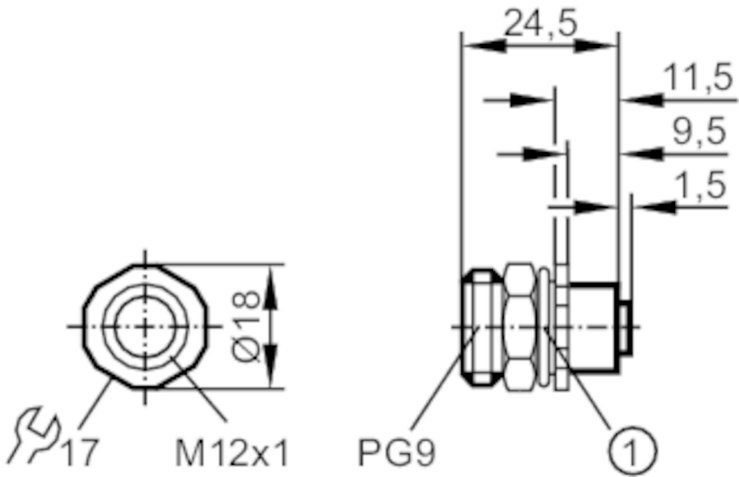

1 O-ring



Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC/DC
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68
Data teknis		
Berat	[g]	22.8
Ulir pemasangan		PG 9
Material		seng tuang
Material bodi detakan		seng tuang
Aksesori		
Item dikirim		mur: 1 x PG9
Keterangan		
Jumlah paket		1 buah

E11067



Soket adaptor

EDOGH040ZDS00,5E04 (PG9)

Koneksi listrik

Kabel: 0.5 m, PVC; 4 x 0.25 mm²

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: seng tuang



Koneksi



BK =
BN =
BU =
WH =

Warna core :
hitam
coklat
biru
putih