




Kabel koneksi Y

YDOAH042MSS0001I04STGH040MSS

Produk tidak tersedia - entri arsip

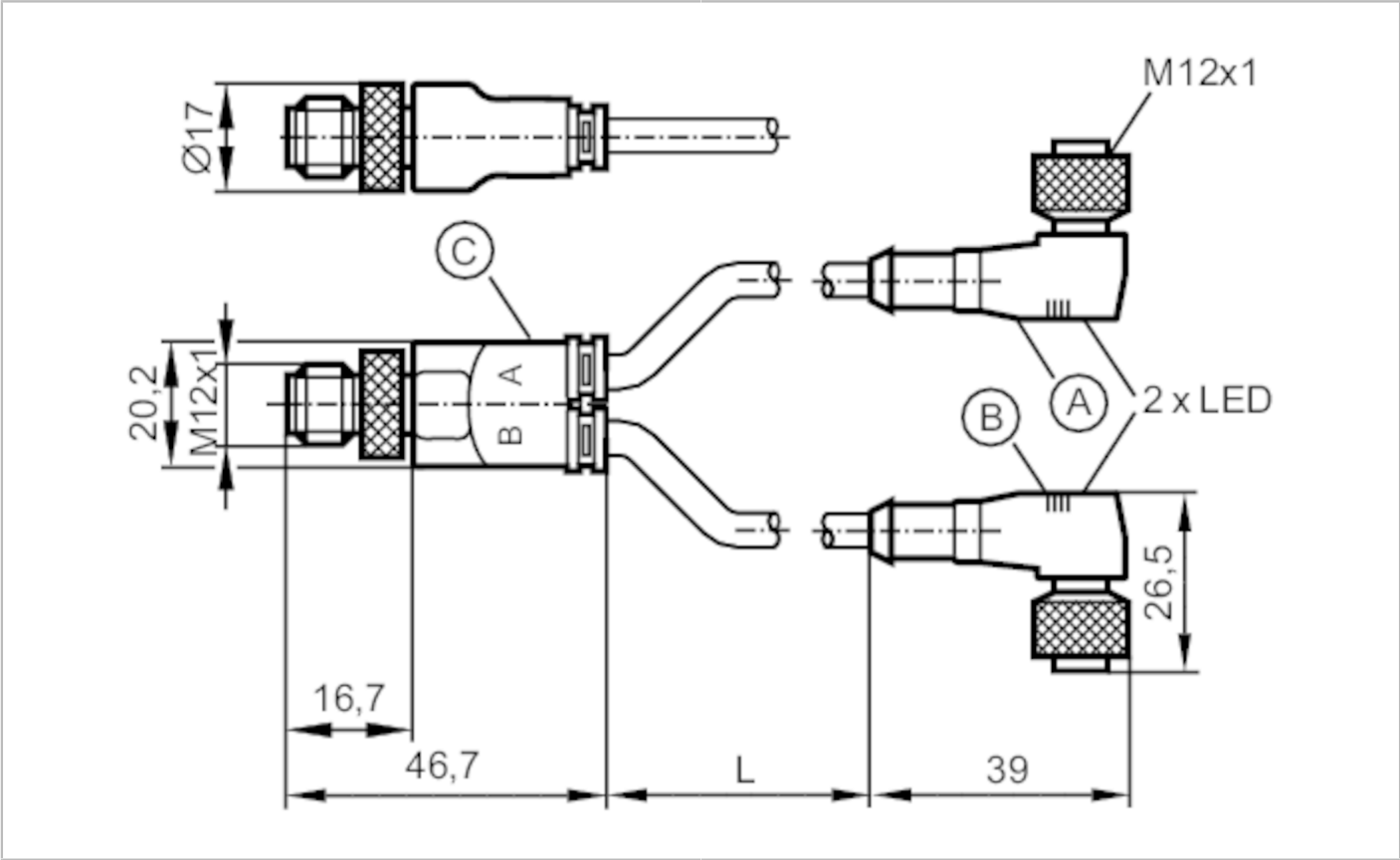

Aplikasi		
Fitur khusus	Bebas halogen	
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan	IP 67	
Data teknis		
Dimensi	[mm]	17 x 20.2 x 46.7
Material	TPU	
Material bodi detakan	TPU	
Material mur	kuningan, berlapis nikel	
Jumlah port kotak splitter	2	
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, merah
	operasi	1 x LED, hijau
Keterangan		
Jumlah paket	1 buah	



Kabel koneksi Y

YDOAH042MSS0001I04STGH040MSS

Koneksi listrik


Kabel: 1 m, PUR, Bebas halogen, hitam, Ø 4.3 mm; 3 x 0.34 mm² (43 x Ø 0.1 mm)

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



Koneksi

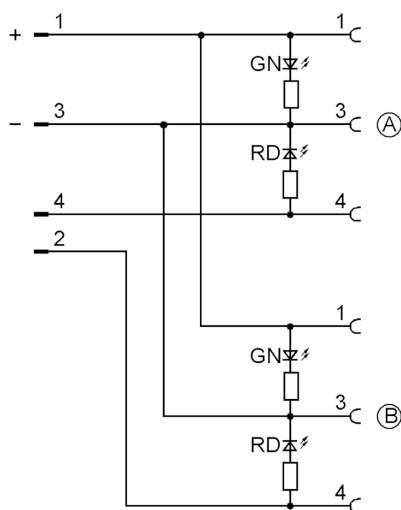

Koneksi listrik - soket

Konektor: 2 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

