


Kabel koneksi dengan soket

ADOGB050MSS0002E05

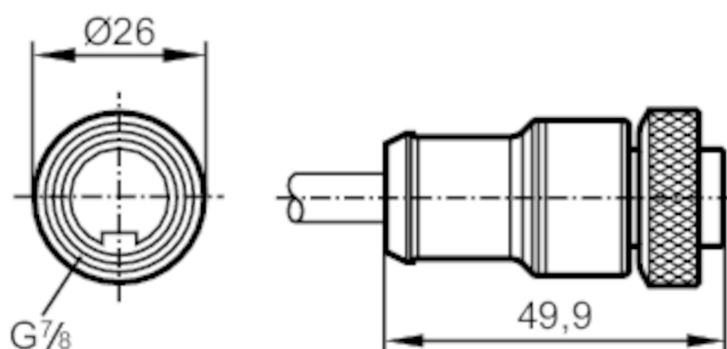

Data kelistrikan

Tegangan pengoperasian	[V]	< 300 AC/DC
Total beban arus maks.	[A]	4

Kondisi pengoperasian

Suhu sekitar	[°C]	-30...80
Suhu sekitar (bergerak)	[°C]	-5...80
Perlindungan		IP 68

Data teknis

Berat	[g]	137.7
Dimensi	[mm]	26 x 26 x 49.9
Material bodi detakan		TPU
Material mur		seng tuang

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E11076



Kabel koneksi dengan soket

ADOGB050MSS0002E05

Koneksi listrik

Kabel: 2 m, PVC, hitam; 5 x 0.5 mm² (16 x Ø 0.2 mm)

Koneksi listrik - soket

Konektor: 1 x 7/8", lurus; Bodi cetakan: TPU; Penguncian: seng tuang



Koneksi

1	BK
2	BU
3	GN/YE
4	BN
5	WH

BK =	Warna core :
BN =	hitam
BU =	coklat
GN/YE =	biru
WH =	hijau/kuning
	putih