




Kabel koneksi dengan soket

ADOAF030VAS0010E03

Produk tidak tersedia - entri arsip

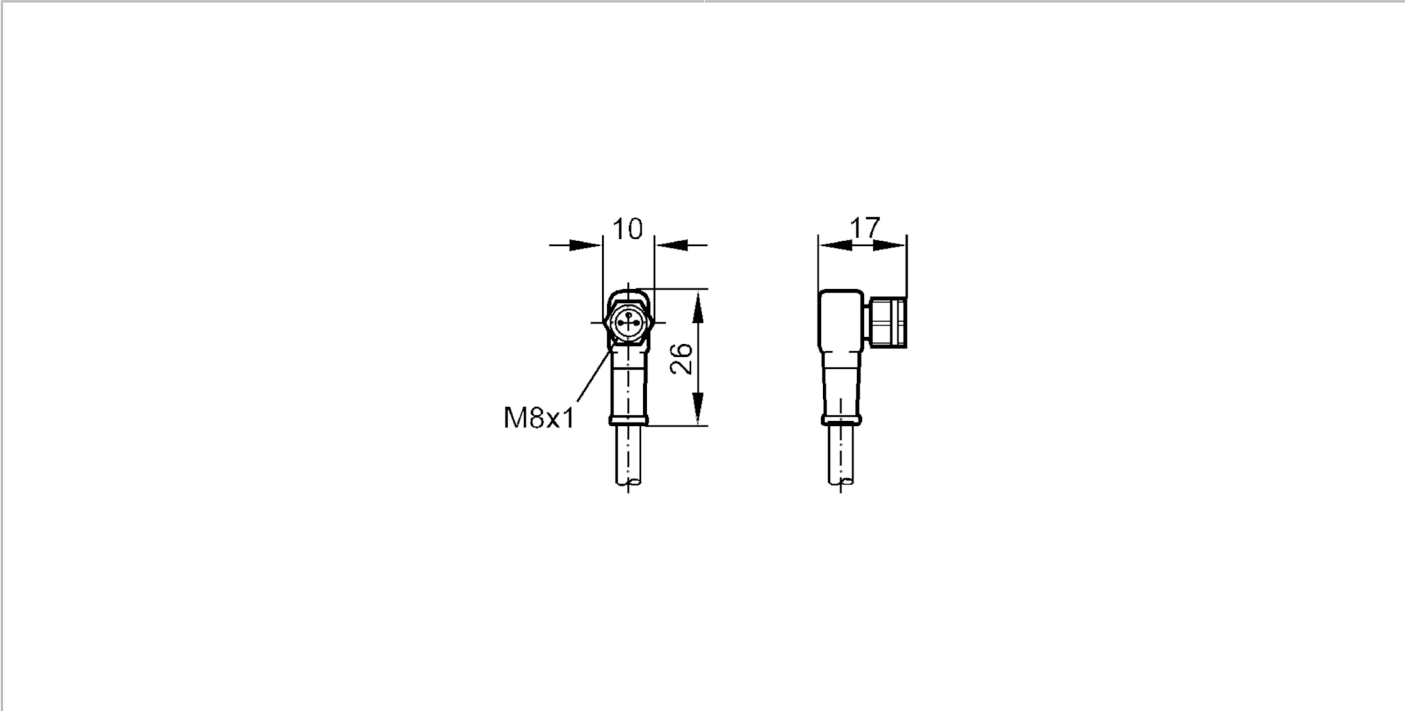

Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC / < 75 DC
Kelas perlindungan		III


Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis		
Dimensi	[mm]	17 x 10 x 26
Material		TPU
Material bodi detakan		TPU
Material mur		baja tahan karat (1.4305/303)

Keterangan		
Jumlah paket		1 buah

Koneksi listrik		
Kabel: 10 m, PVC, oranye, Ø 5 mm; 3 x 0.34 mm²		

Koneksi listrik - soket		
Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: baja tahan karat (1.4305/303)		

 

E11090



Kabel koneksi dengan soket

ADOAF030VAS0010E03

Koneksi



BN =	Warna core :	coklat
BK =		hitam
BU =		biru