


Kabel koneksi

VDOAH043MSS0002H04STGH040MSS

Produk tidak tersedia - entri arsip

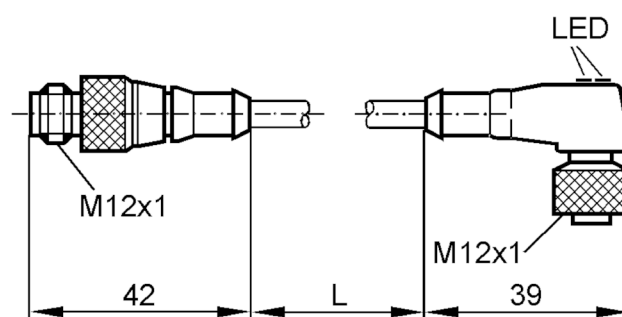

Aplikasi

Fitur khusus	Bebas halogen
--------------	---------------

Data kelistrikan

Tegangan pengoperasian [V]	10...30 DC
----------------------------	------------

Kondisi pengoperasian

Suhu sekitar [°C]	-25...90
-------------------	----------

Perlindungan	IP 67
--------------	-------

Data teknis

Material	TPU
Material bodi detakan	TPU
Material mur	kuningan, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	2 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

Kabel koneksi

VDOAH043MSS0002H04STGH040MSS

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



Koneksi listrik

Kabel: 2 m, PUR, Bebas halogen, hitam, Ø 4.7 mm; 4 x 0.34 mm²

Koneksi

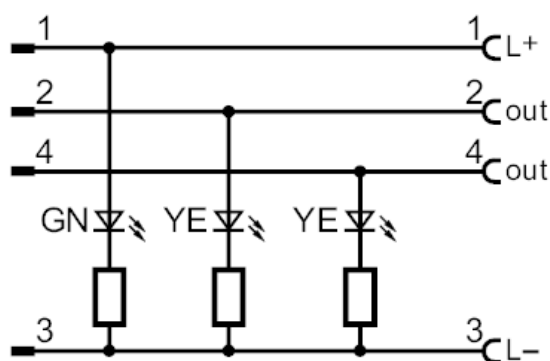

Warna core :

BK = hitam

BN = coklat

BU = biru

WH = putih

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

