




Kabel koneksi dengan soket

ADOGF030VAS0020E03

Produk tidak tersedia - entri arsip

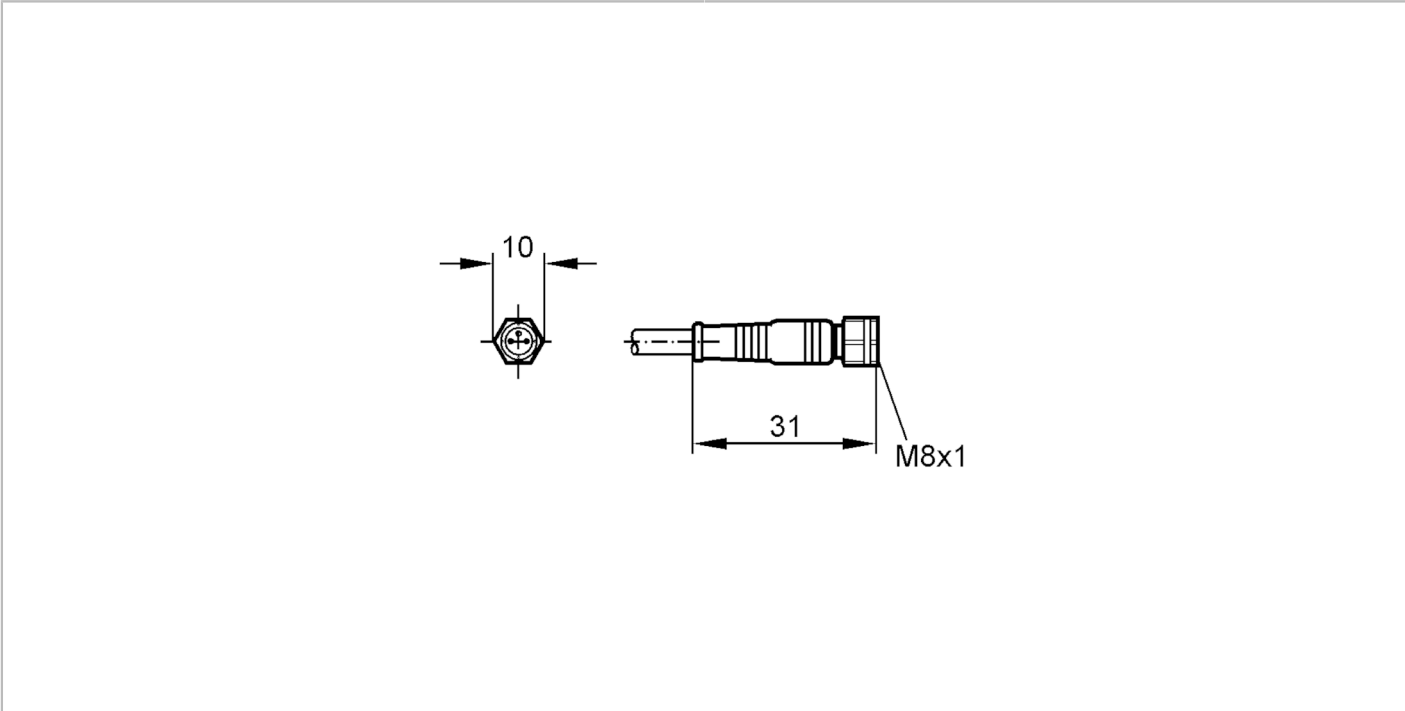

Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC / < 75 DC
Kelas perlindungan		III


Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67; (jika dipasang dengan sekrup)

Data teknis		
Dimensi	[mm]	10 x 10 x 31
Material		TPU
Material bodi detakan		TPU
Material mur		baja tahan karat (1.4305/303)

Keterangan		
Jumlah paket		1 buah

Koneksi listrik		
Kabel: 20 m, PVC, oranye, Ø 5 mm; 3 x 0.34 mm ² (42 x Ø 0.1 mm)		

Koneksi listrik - soket		
Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: baja tahan karat (1.4305/303)		

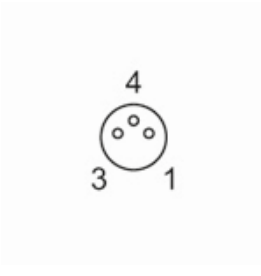


E11097



Kabel koneksi dengan soket

ADOGF030VAS0020E03

Koneksi

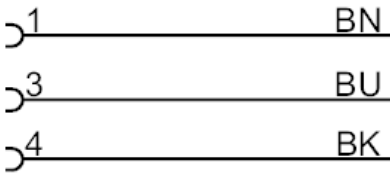

BN =	Warna core :	coklat
BK =		hitam
BU =		biru