




Kabel koneksi dengan colokan

ASTGH040MSS0002E04

Produk tidak tersedia - entri arsip

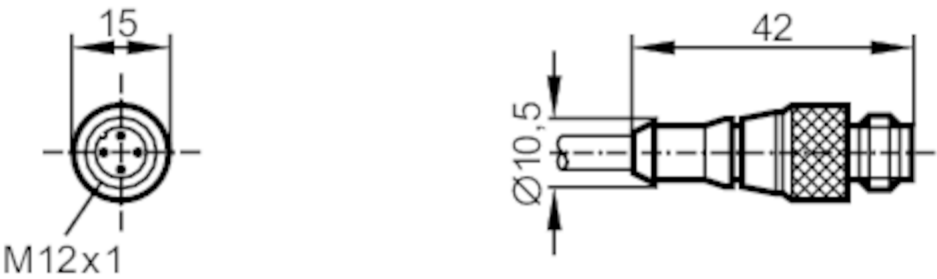

Data kelistrikan		
Tegangan pengoperasian	[M]	< 250 AC / < 300 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...70
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	15 x 15 x 42
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 2 m, PVC, oranye, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)		
Koneksi listrik - colokan		

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



E11104



Kabel koneksi dengan colokan

ASTGH040MSS0002E04

Koneksi

1	BN
2	WH
3	BU
4	BK

BK = Warna core :
BN = hitam
BU = coklat
WH = biru
 putih