




Kabel koneksi dengan soket

ADOAF030MSS0010A03

Produk tidak tersedia - entri arsip

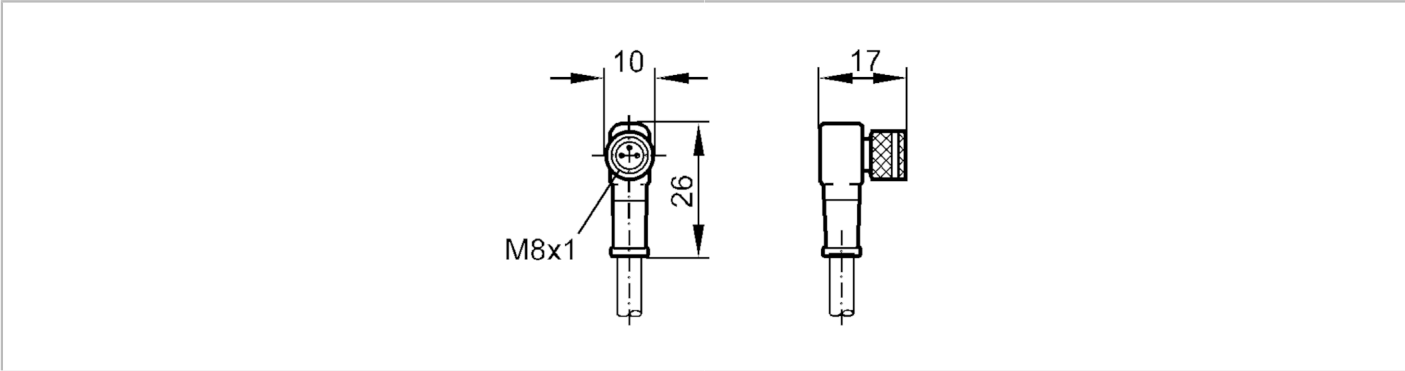

Data kelistrikan

|                            |                   |
|----------------------------|-------------------|
| Tegangan pengoperasian [M] | < 60 AC / < 75 DC |
| Kelas perlindungan         | III               |

Kondisi pengoperasian

|                   |          |
|-------------------|----------|
| Suhu sekitar [°C] | -25...90 |
| Perlindungan      | IP 67    |

Data teknis

|                       |                          |
|-----------------------|--------------------------|
| Material              | TPU                      |
| Material bodi detakan | TPU                      |
| Material mur          | kuningan, berlapis nikel |

Keterangan


|              |        |
|--------------|--------|
| Jumlah paket | 1 buah |
|--------------|--------|

Koneksi listrik

Kabel: 10 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm )

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

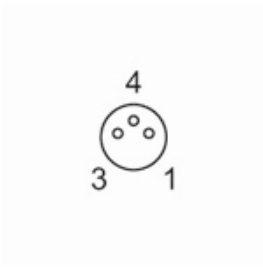


# E11130



## Kabel koneksi dengan soket

ADOAF030MSS0010A03

### Koneksi

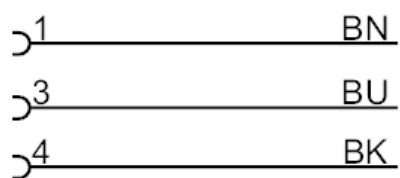

|      |              |        |
|------|--------------|--------|
| BN = | Warna core : | coklat |
| BK = |              | hitam  |
| BU = |              | biru   |