


E11145



Soket berkabel

SDOGH040PLSFKSK

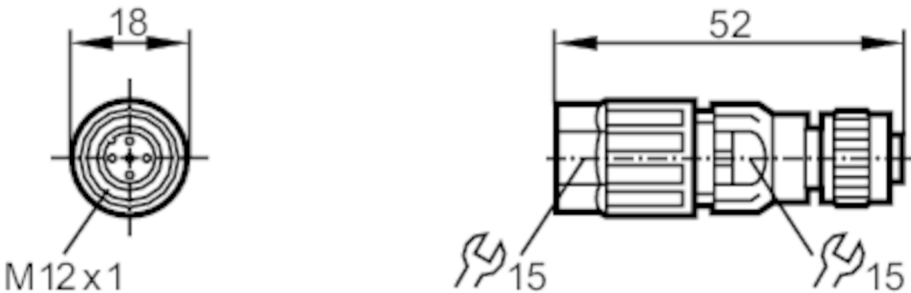

Data kelistrikan

Tegangan pengoperasian	[V]	< 45 AC / < 70 DC
Total beban arus maks.	[A]	4

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...60
Perlindungan		IP 67

Data teknis

Berat	[g]	13.5
Dimensi	[mm]	18 x 18 x 52
Material		PA 6.6
Material bodi detakan		PA 6.6
Material mur		PA 6.6

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

teknologi perpindahan isolasi: 0.34...0.75 mm²; Isolasi core: PVC / PE; (Ø ...2.5 mm); Selubung kabel: Ø 4...7.5 mm

Koneksi listrik - soket

 Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PA 6.6; Penguncian: PA 6.6



E11145

Soket berkabel

SDOGH040PLSFKSK



Koneksi

