


Kabel koneksi

VDOAH043MSS0003H04STGH040MSS

Produk tidak tersedia - entri arsip

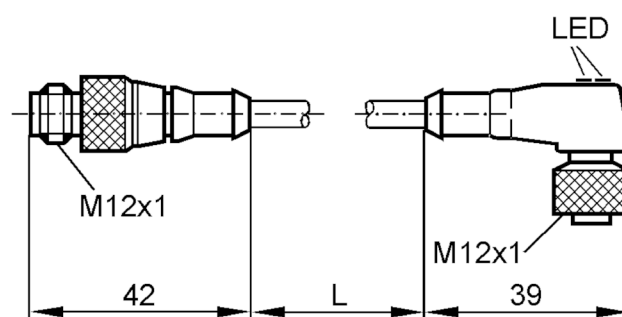

Aplikasi

Fitur khusus

Bebas halogen

Data kelistrikan

Tegangan pengoperasian

[V]

10...30 DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-25...90

Perlindungan

IP 67

Data teknis

Material

TPU

Material bodi detakan

TPU

Material mur

kuningan, berlapis nikel

Elemen display/pengoperasian

Display

status peralihan

2 x LED, kuning

operasi

1 x LED, hijau

Keterangan

Jumlah paket

1 buah



Kabel koneksi

VDOAH043MSS0003H04STGH040MSS

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



Koneksi listrik

Kabel: 3 m, PUR, Bebas halogen, hitam, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Koneksi

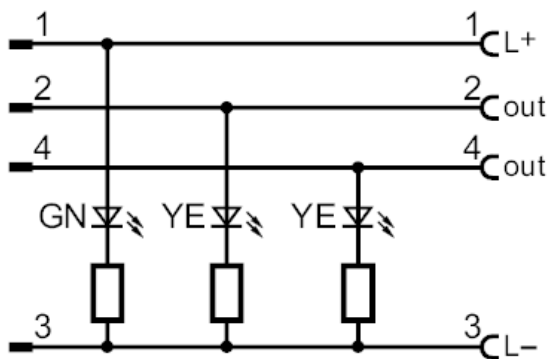

BK = Warna core :
BN = hitam
BU = coklat
WH = biru
 putih

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

