


E11157



Kabel jumper dengan soket katup

VVDAB031--S01,5H03STGH030MSS

Produk tidak tersedia - entri arsip

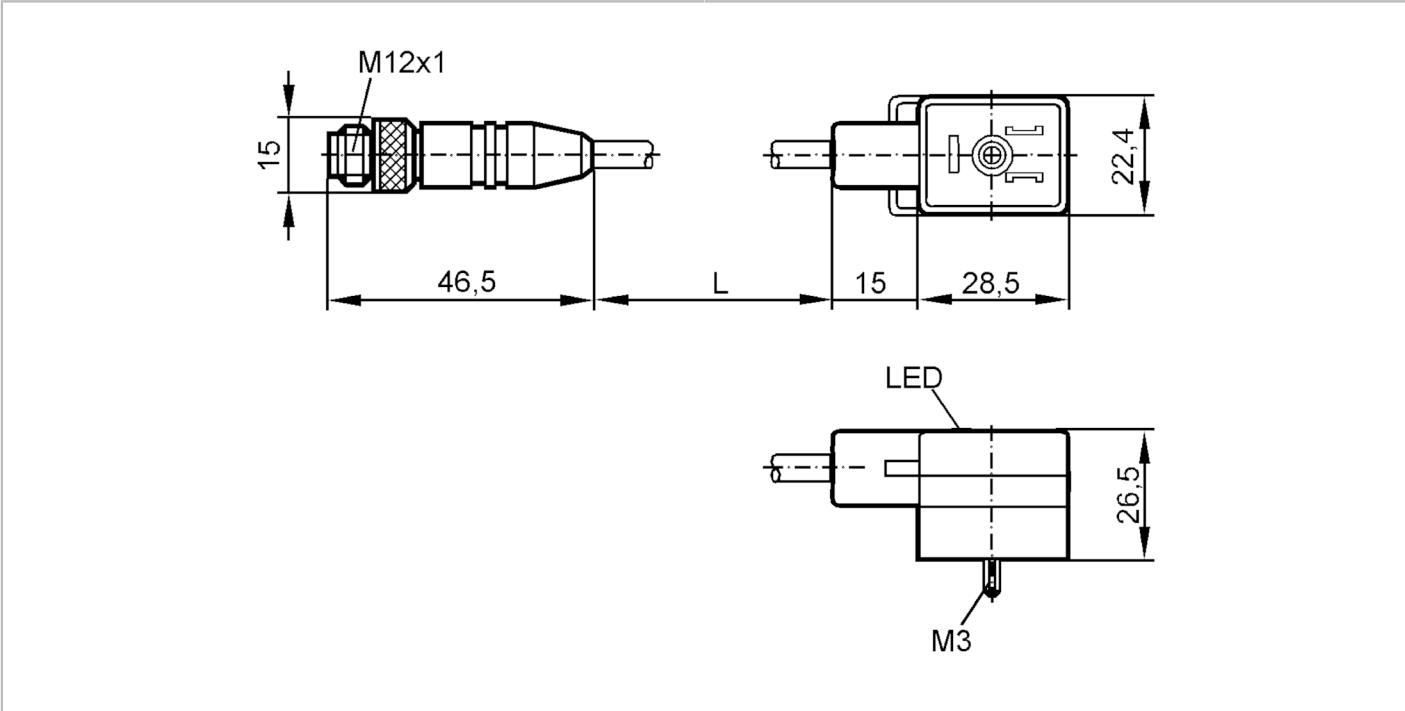


Aplikasi		
Fitur khusus	Bebas halogen	
Data kelistrikan		
Tegangan pengoperasian	[V]	< 24 AC/DC
Pelindung tegangan berlebih	ya; (VDR)	
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan	IP 67	
Data teknis		
Dimensi	[mm]	15 x 15 x 46.5
Material	TPU	
Material bodi detakan	TPU	
Material mur	kuningan, berlapis nikel	
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Aksesori		
Item dikirim	sekrup	
	panel untuk pelabelan	
Keterangan		
Jumlah paket	1 buah	

Kabel jumper dengan soket katup

VVDAB031--S01,5H03STGH030MSS

Koneksi listrik - colokan

 
Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



Koneksi listrik

Kabel: 1.5 m, PUR, Bebas halogen; 3 x 0.5 mm²

Koneksi

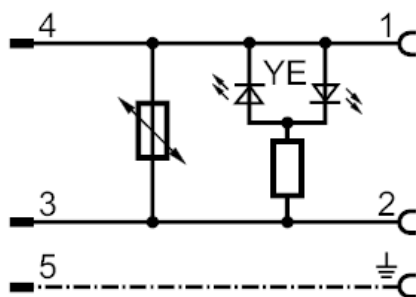

Koneksi listrik - soket

Konektor: 1 x katup tipe B DIN, bersiku; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

