




Kabel koneksi dengan soket

ADOGG040--S0005A03

Produk tidak tersedia - entri arsip

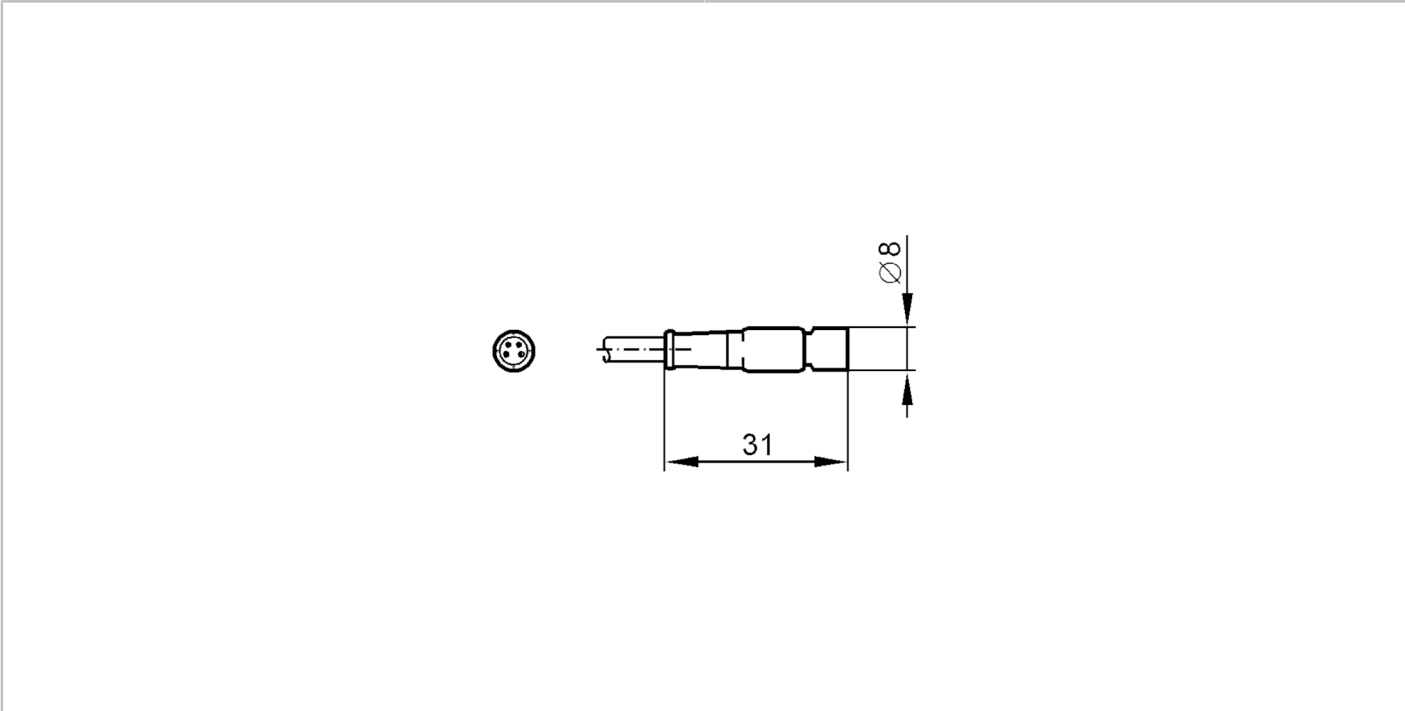

Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC / < 75 DC
Kelas perlindungan		III


Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 65

Data teknis		
Dimensi	[mm]	8 x 8 x 31
Material		TPU
Material bodi detakan		TPU

Keterangan		
Jumlah paket		1 buah

Koneksi listrik		
Kabel: 5 m, PUR / PVC, oranye, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)		

Koneksi listrik - soket		
Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU		
Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU		

 



Kabel koneksi dengan soket

ADOGG040--S0005A03

Koneksi



BK = Warna core :
BN = hitam
BU = coklat
WH = biru
 putih