


E11190



Colokan adaptor

ESTGF040MSS00,5E04 (M8)

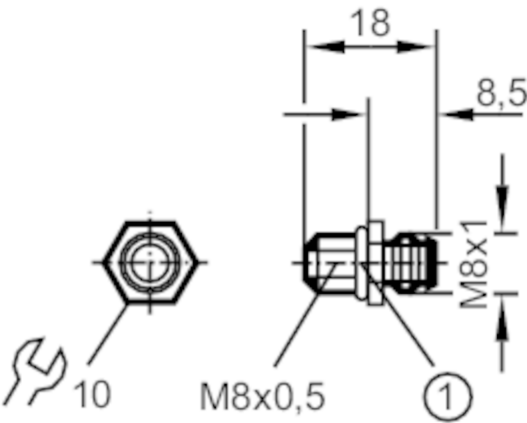

1 O-ring



Data kelistrikan		
Tegangan pengoperasian	[V]	< 45 AC / < 70 DC
Kelas perlindungan		III
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	11.6
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah



Colokan adaptor

 
ESTGF040MSS00,5E04 (M8)

Koneksi listrik

Kabel: 0.5 m, PVC; 4 x 0.25 mm²

Koneksi listrik - colokan

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel



Koneksi

1	BN
2	WH
3	BU
4	BK

BK =	Warna core :
BN =	hitam
BU =	coklat
WH =	biru
	putih