


Kotak splitter

ZDO8F039MSS0005H10

Produk tidak tersedia - entri arsip

Produk alternatif: EBC054

Ketika memilih produk dan aksesoris alternatif, perhatikan bahwa data teknis mungkin berbeda!

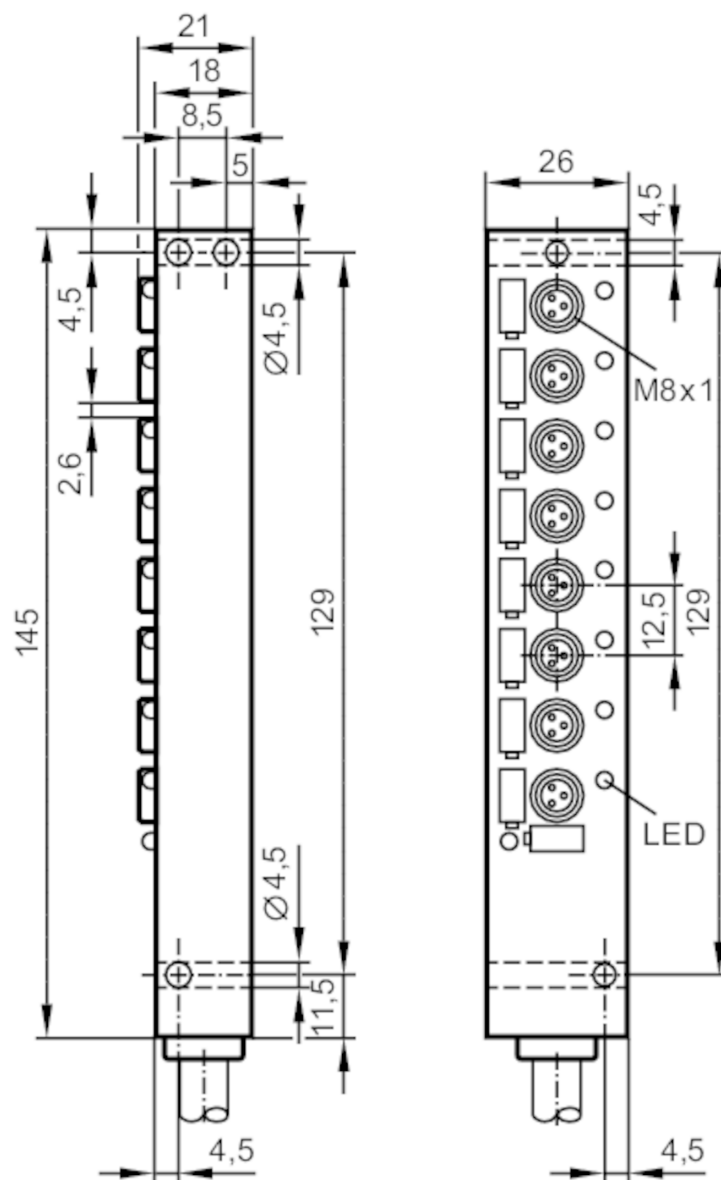

Aplikasi

Fitur khusus

Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
Kelas perlindungan		III
Beban arus maks. per modul/slot	[A]	2
Total beban arus maks.	[A]	6



Kotak splitter

ZDO8F039MSS0005H10

Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68
Data teknis		
Berat	[g]	663
Dimensi	[mm]	21 x 26 x 145
Material		PBT-GF20; kuningan berlapis nikel
Material bodi detakan		PBT-GF 20 / kuningan, berlapis nikel
Jumlah port kotak splitter		8
Tipe konektor		M8
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	kecepatan pergerakan	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk²
	siklus pembengkokan	> 5 Mio.
	ketegangan torsional	± 180 °/m
Elemen display/pengoperasian		
Display	status peralihan	8 x LED, kuning
	operasi	1 x LED, hijau
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 9.1 mm; 8 x 0.34 mm² (42 x Ø 0.1 mm) + 2 x 0.75 mm² (96 x Ø 0.1 mm)		
Koneksi listrik - slot		
Konektor: 8 x M8; pengkodean: A; Bodi cetakan: PBT-GF 20 / kuningan, berlapis nikel; Kontak: dilapisi emas		
		

E11214



Kotak splitter

ZDO8F039MSS0005H10

Koneksi



	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning