


E11228



Kabel koneksi Y

YDOGH080MSS0,15H08STGH040MSS

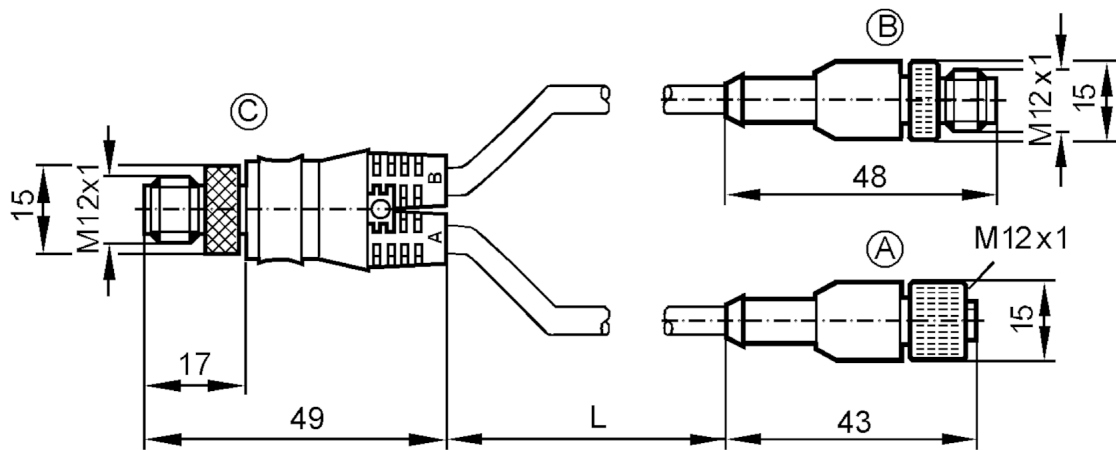

Aplikasi	
Fitur khusus	Bebas halogen
Data kelistrikan	
Tegangan pengoperasian [V]	< 30 AC / < 36 DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-25...80
Perlindungan	IP 68
Data teknis	
Berat [g]	63
Material	PUR
Material bodi detakan	PUR
Material mur	kuningan, berlapis nikel
Keterangan	
Jumlah paket	1 buah

Koneksi listrik - soket A


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel



Kabel koneksi Y

YDOGH080MSS0,15H08STGH040MSS

Koneksi

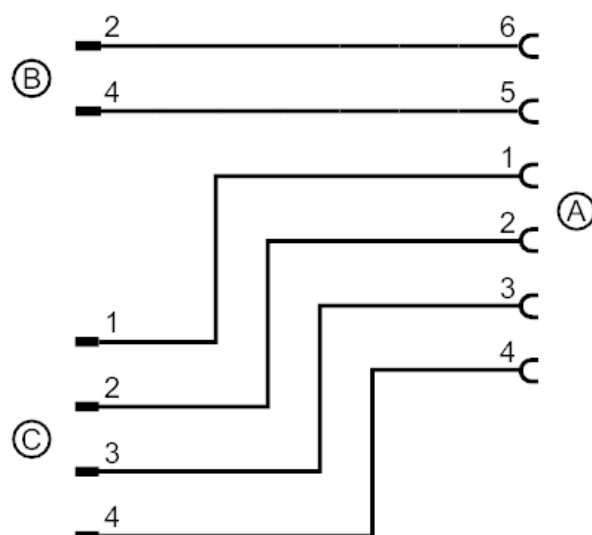

Koneksi listrik - colokan B

Kabel: 0.15 m, PUR, Bebas halogen, hitam, Ø 6.2 mm; 2 x 0.25 mm²

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel



Koneksi listrik - colokan C

Kabel: 0.15 m, PUR, Bebas halogen, hitam, Ø 6.2 mm; 4 x 0.25 mm²

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

