


E11230



Kabel koneksi

VDOGH080MSS0005H08STGH080MSS

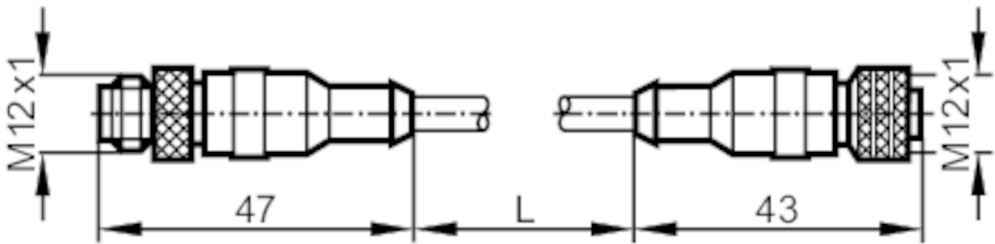


Aplikasi	
Fitur khusus	Bebas halogen
Data kelistrikan	
Tegangan pengoperasian [V]	< 30 AC / < 36 DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-25...80
Perlindungan	IP 68
Data teknis	
Berat [g]	331.8
Material	PUR
Material bodi detakan	PUR
Material mur	kuningan, berlapis nikel
Keterangan	
Jumlah paket	1 buah

Kabel koneksi

VDOGH080MSS0005H08STGH080MSS

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.7...0.9 Nm

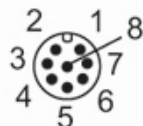

Koneksi listrik

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 6.8 mm; 8 x 0.25 mm²

Koneksi

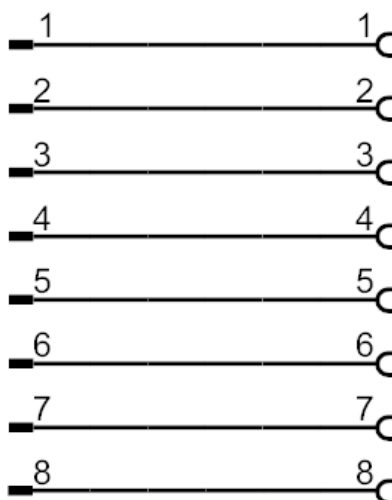

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.7...0.9 Nm

