



Kabel koneksi

VDOAH040MSS0003E04STGH040MSS


Produk tidak tersedia - entri arsip



Data kelistrikan	
Tegangan pengoperasian	[V] < 250 AC / < 300 DC
Kondisi pengoperasian	
Suhu sekitar	[°C] -25...70
Perlindungan	IP 67
Data teknis	
Material	TPU
Material bodi detakan	TPU
Material mur	kuningan, berlapis nikel
Keterangan	
Jumlah paket	1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

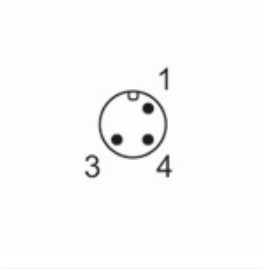



Kabel koneksi

VDOAH040MSS0003E04STGH040MSS

Koneksi listrik

Kabel: 3 m, PVC; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

