


E11246



Kabel koneksi dengan soket

ADOGB050PLS0005E05

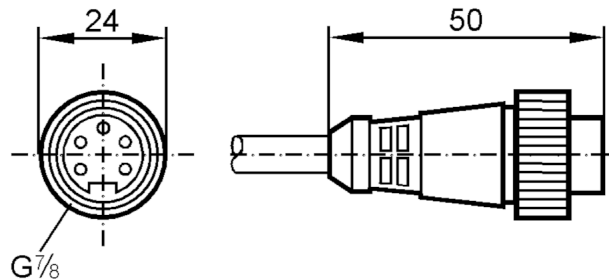

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC
Total beban arus maks.	[A]	5

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...90
Perlindungan		IP 68

Data teknis

Berat	[g]	498.2
Dimensi	[mm]	24 x 24 x 50
Material		TPU
Material bodi detakan		TPU
Material mur		TPU

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 5 m, PVC; 5 x 0.75 mm² / AWG 18

Koneksi listrik - soket

Konektor: 1 x 7/8", lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: TPU






Kabel koneksi dengan soket

AD0GB050PLS0005E05

Koneksi

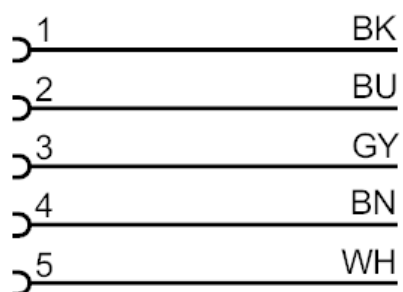

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GY =	abu-abu
WH =	putih