


E11249

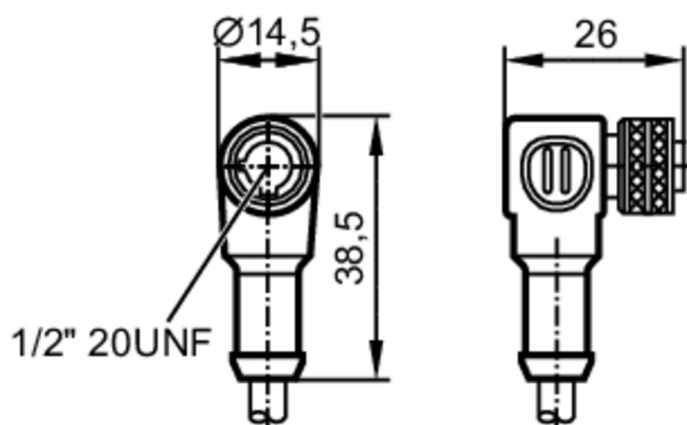

Kabel koneksi dengan soket

ADOAA050MSS0010H04



Aplikasi

Fitur khusus

Bebas halogen

Data kelistrikan

Tegangan pengoperasian

[V]

< 300 AC

Kondisi pengoperasian

Suhu sekitar

[°C]

-25...90

Perlindungan

IP 67

Data teknis

Berat

[g]

322.7

Material

TPU

Material bodi detakan

TPU

Material mur

kuningan, berlapis nikel

Keterangan

Jumlah paket

1 buah

E11249



Kabel koneksi dengan soket

ADOAA050MSS0010H04

Koneksi listrik


Kabel: 10 m, PUR, Bebas halogen, hitam, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x 1/2", bersiku; pengkodean: C; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



Koneksi

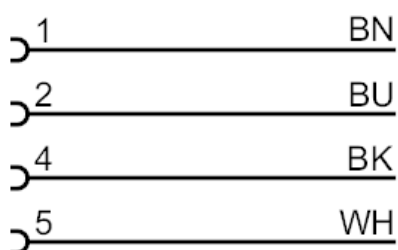

BK =	Warna core :
BN =	hitam
BU =	coklat
WH =	biru
	putih