


E11251



Kabel koneksi dengan soket

ADOGA050MSS0010H04

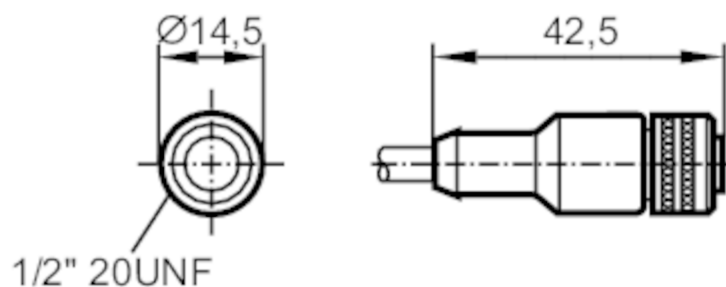

Aplikasi		
Fitur khusus		Bebas halogen
Data kelistrikan		
Tegangan pengoperasian	[V]	< 300 AC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Berat	[g]	312.402
Dimensi	[mm]	14.5 x 14.5 x 42.5
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E11251



Kabel koneksi dengan soket

ADOGA050MSS0010H04

Koneksi listrik


Kabel: 10 m, PUR, Bebas halogen, hitam, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x 1/2", lurus; pengkodean: C; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



Koneksi

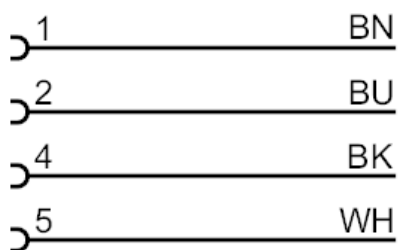

BK =	Warna core :
BN =	hitam
BU =	coklat
WH =	biru
	putih