


E11252



Soket berkabel

SDOAH040VASFKPG

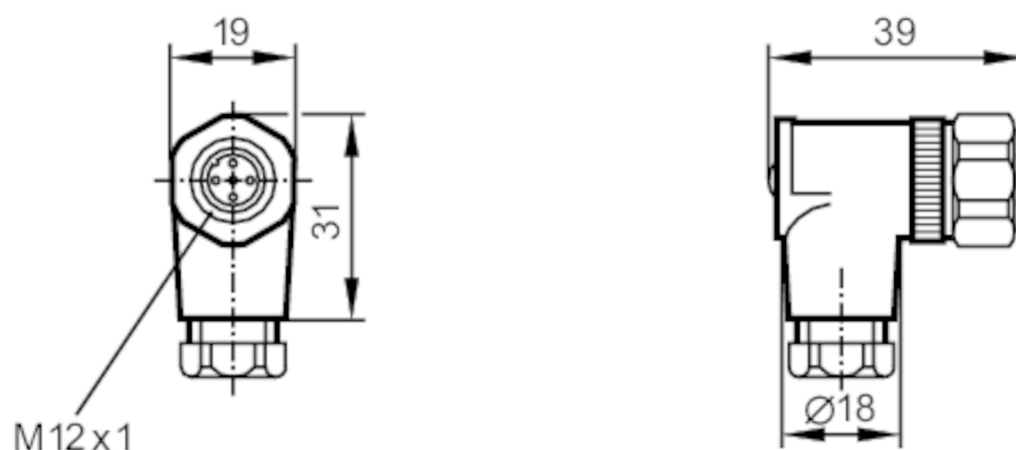

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	< 45 AC / < 70 DC
Total beban arus maks.	[A]	4; (...40 °C)

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...85
Perlindungan		IP 68

Data teknis

Berat	[g]	28.2
Dimensi	[mm]	39 x 19 x 31
Material		PBT
Material bodi detakan		PBT
Material mur		baja tahan karat (1.4404 / 316L)

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E11252



Soket berkabel

 
SDOAH040VASFKPG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 6...8 mm

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PBT; Penguncian: baja tahan karat (1.4404 / 316L); Kontak: dilapisi emas



Koneksi

