


Colokan adaptor

ESTGH040MSS0,05E04 (M20)

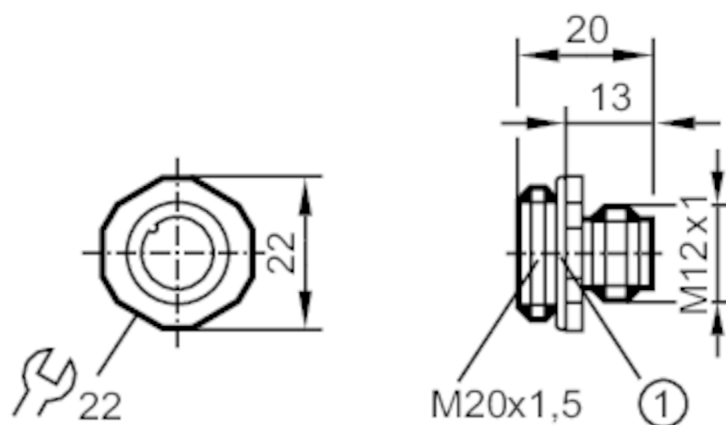

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC/DC
------------------------	-----	-------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68

Data teknis

Berat	[g]	22.6
Ulir pemasangan		M20
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

Kabel: 0.05 m, PVC; 4 x 0.25 mm²

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel





Colokan adaptor

ESTGH040MSS0,05E04 (M20)

Koneksi

1	BN
2	WH
3	BU
4	BK

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
WH =	putih