



Kabel koneksi


VDOGH040MSS0005H04STGH040MSS

Produk tidak tersedia - entri arsip



Aplikasi	
Fitur khusus	Bebas halogen
Data kelistrikan	
Tegangan pengoperasian [V]	< 250 AC / < 300 DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-25...80
Perlindungan	IP 68
Data teknis	
Material	PUR
Material bodi detakan	PUR
Material mur	kuningan, berlapis nikel
Keterangan	
Jumlah paket	1 buah
Koneksi listrik - colokan	

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

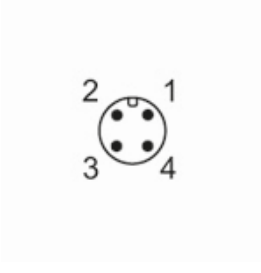

**Kabel koneksi**

VDOGH040MSS0005H04STGH040MSS

Koneksi listrikKabel: 2 m, PUR, Bebas halogen, hitam, Ø 4.9 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)**Koneksi****Koneksi listrik - soket**

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

