


E11315



Colokan adaptor

ESTGH050MSS00,5E05 (M20)

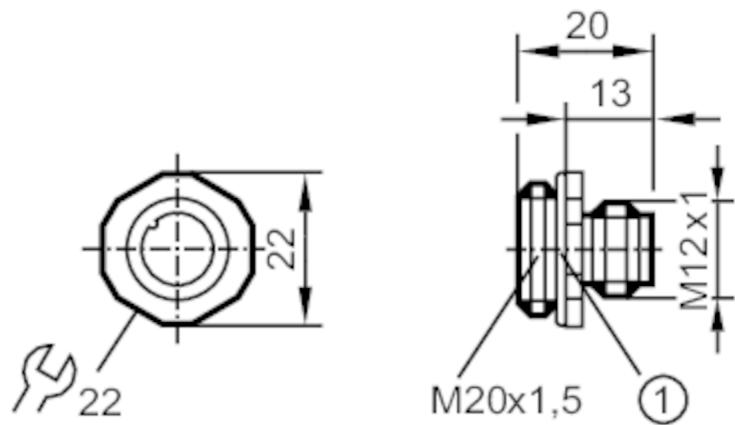

Data kelistrikan		
Tegangan pengoperasian	[V]	< 125 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68
Data teknis		
Berat	[g]	27.3
Dimensi	[mm]	18 x 18 x 19
Ulir pemasangan		M20
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E11315



Colokan adaptor


ESTGH050MSS00,5E05 (M20)

Koneksi listrik

Kabel: 0.5 m, PVC; 4 x 0.25 mm² + 1 x 0.5 mm²

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel; Torsi pengencangan: ...0.6 Nm; ulir M20 Torsi pengencangan: ...2 Nm

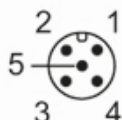

Koneksi

1	BN
2	WH
3	BU
4	BK
5	GN/YE

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
WH =	putih
YE =	kuning