


E12405



Kabel koneksi Y

YDOGH050MSS0,25H04STGH050MSS

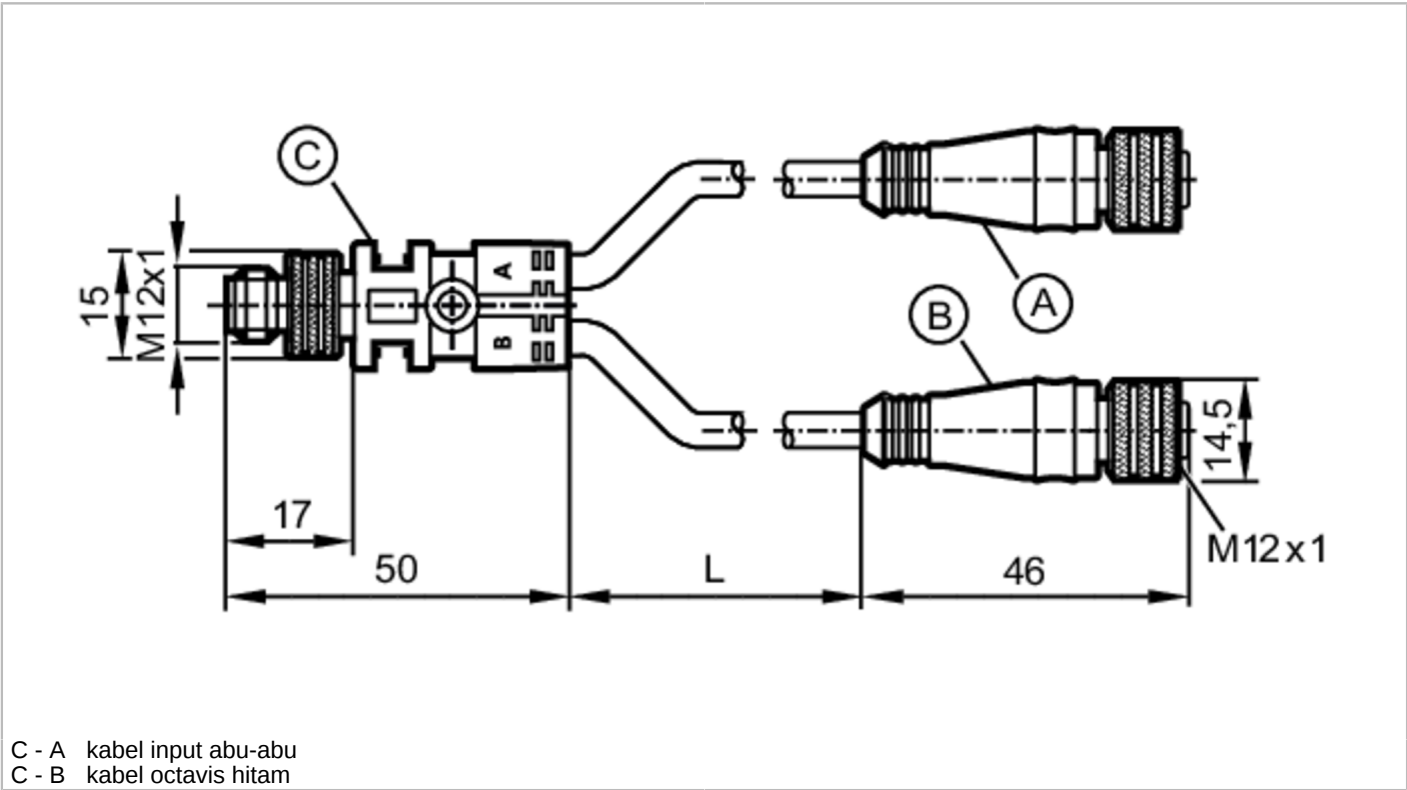

Aplikasi		
Fitur khusus		Bebas halogen
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Berat	[g]	65
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Jumlah port kotak splitter		2
Keterangan		
Jumlah paket		1 buah




Kabel koneksi Y


YDOGH050MSS0,25H04STGH050MSS

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

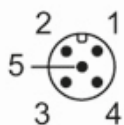

Koneksi

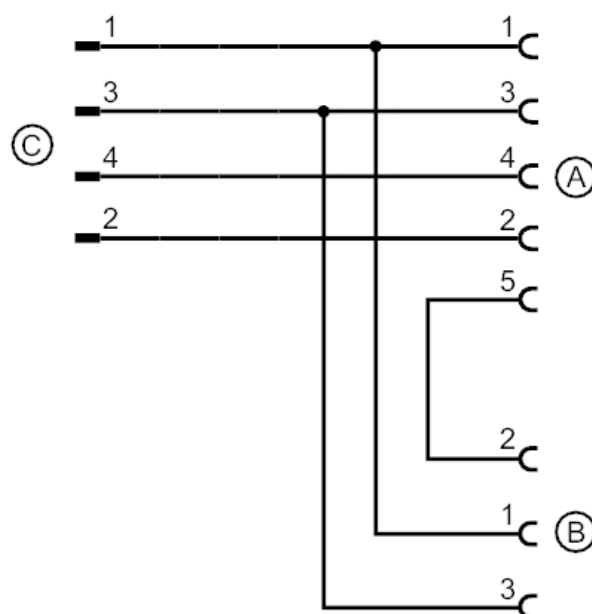

Koneksi listrik - soket

Kabel: 0.25 m, PUR, Bebas halogen, hitam, Ø 5.0 mm; 5 x 0.25 mm² (32 x Ø 0.1 mm)

Konektor: 2 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

