


E12422



Kabel koneksi Ethernet

VSTGN040ZDS00,5L04STGN040ZDS

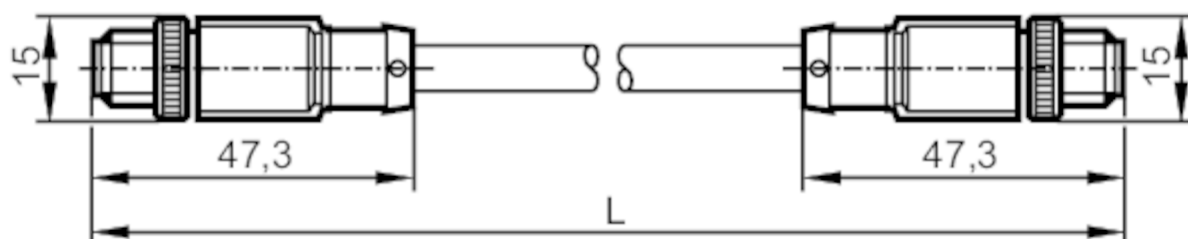

Aplikasi

Fitur khusus	Kontak berlapis emas; Kabel berpelindung
Desain	Kabel Ethernet, Dengan kode D

Data kelistrikan

Tegangan pengoperasian [V]	< 50 AC / < 60 DC
Kelas perlindungan	III
Total beban arus maks. [A]	4

Kondisi pengoperasian

Suhu sekitar [°C]	-20...90
Perlindungan	IP 67

Data teknis

Berat [g]	66.1
Dimensi [mm]	15 x 15 x 47.3
Material	TPU
Material bodi detakan	TPU
Material mur	seng tuang, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

Kabel koneksi Ethernet

VSTGN040ZDS00,5L04STGN040ZDS

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: pelindung terhubung



Koneksi listrik

Kabel: 0.5 m, PVC, hijau, berpelindung; 4 x 0.34 mm²

Koneksi



Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: pelindung terhubung

