


Kabel koneksi Ethernet

VSTGN040ZDS0020L04STGN040ZDS

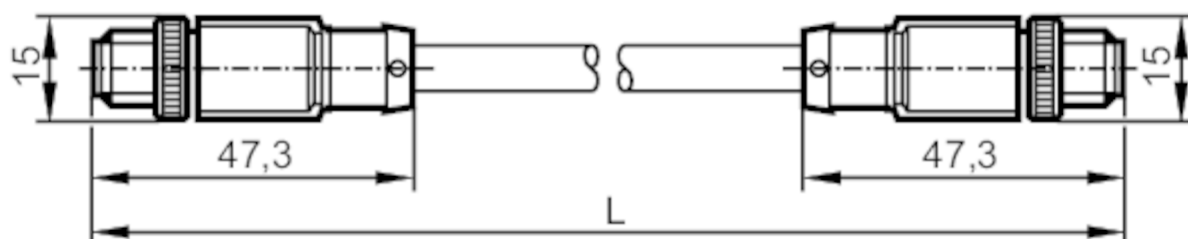

Aplikasi

Fitur khusus

Kontak berlapis emas; Kabel berpelindung

Desain

Kabel Ethernet, Dengan kode D

Data kelistrikan

Tegangan pengoperasian

[V]

< 50 AC / < 60 DC

Kelas perlindungan

III

Total beban arus maks.

[A]

4

Kondisi pengoperasian

Suhu sekitar

[°C]

-20...90

Perlindungan

IP 67

Data teknis

Berat

[g]

1369

Dimensi

[mm]

15 x 15 x 47.3

Material

TPU

Material bodi detakan

TPU

Material mur

seng tuang, berlapis nikel

Keterangan

Jumlah paket

1 buah

Kabel koneksi Ethernet

VSTGN040ZDS0020L04STGN040ZDS

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: pelindung terhubung



Koneksi listrik

Kabel: 20 m, PVC, hijau, berpelindung; 4 x 0.34 mm²

Koneksi

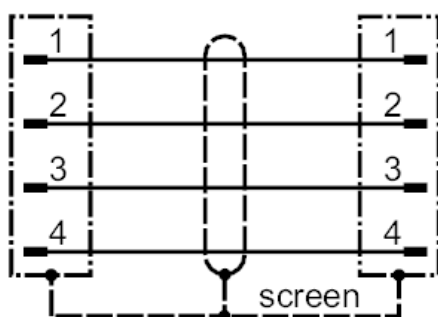

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: pelindung terhubung

