


E12437

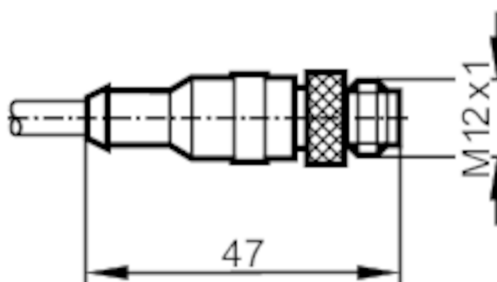

Kabel koneksi dengan colokan

ASTGH080MSS0005H08



Data kelistrikan

Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
------------------------	-----	-------------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
--------------	------	----------

Perlindungan		IP 67
--------------	--	-------

Data teknis

Berat	[g]	313.7
-------	-----	-------

Material		PUR
----------	--	-----

Material bodi detakan		PUR
-----------------------	--	-----

Material mur		kuningan, berlapis nikel
--------------	--	--------------------------

Keterangan

Jumlah paket		1 buah
--------------	--	--------

Kabel koneksi dengan colokan


ASTGH080MSS0005H08

Koneksi listrik

Kabel: 5 m, PUR, hitam, Ø 6.8 mm; 8 x 0.25 mm²

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.7...0.9 Nm

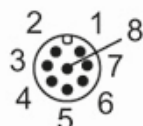

Koneksi

1	BN
2	WH
3	BU
4	BK
5	GY
6	PK
7	VT
8	OG

warna sesuai DIN EN 60947-5-2

Warna core :

BK =	hitam
BN =	coklat
BU =	biru
GY =	abu-abu
PK =	merah muda
OG =	oranye
VT =	ungu
WH =	putih