


E12460




Kabel koneksi

ADOGH080MSS00,3K05STGK120MSS

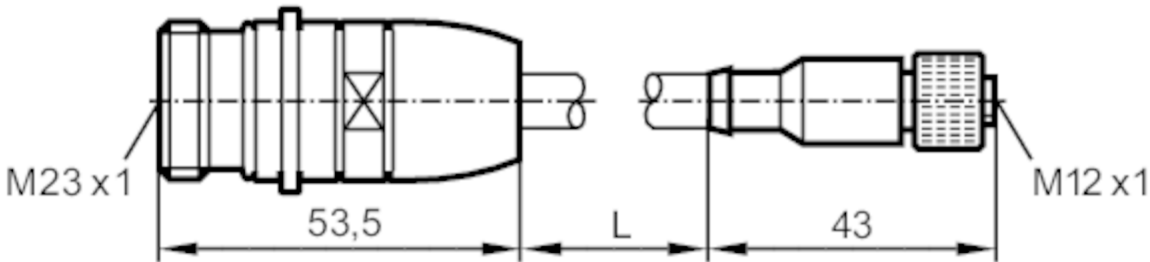

Aplikasi	
Fitur khusus	Kontak berlapis emas; Kabel berpelindung
Data kelistrikan	
Tegangan pengoperasian [V]	< 30 AC / < 36 DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-20...90
Perlindungan	IP 67
Data teknis	
Berat [g]	111.4
Material bodi detakan	kuningan, berlapis nikel / TPU
Material mur	kuningan, berlapis nikel
Keterangan	
Jumlah paket	1 buah
Koneksi listrik - colokan	

Konektor: 1 x M23, lurus; Bodi cetakan: kuningan, berlapis nikel; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: pelindung terhubung

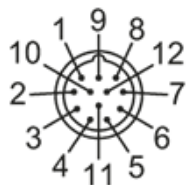




Kabel koneksi

ADOGH080MSS00,3K05STGK120MSS

Koneksi listrik

Kabel: 0.3 m, PUR, hitam, Ø 6 mm, berpelindung; 8 x 0.25 mm²

Koneksi

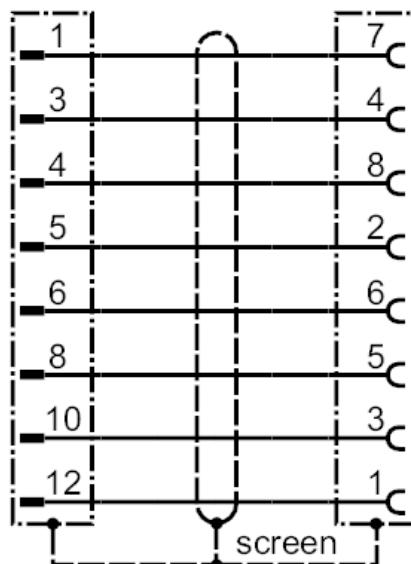

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU, hitam; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas;
Kabel koneksi berpelindung: pelindung terhubung

